

EA986MB- 100




EAN: 4047526005450

ID: 5454

Nylon wheel

Tyre & running tread: Made of high-quality, impact-resistant nylon. Tread colour: natural white
Rim / wheel centre: -

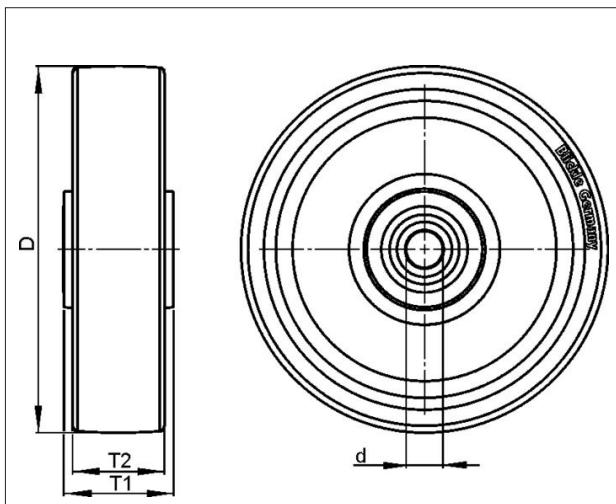

Technical data

Wheel Ø (D)	100 mm
Wheel width (T2)	37 mm
Load capacity	280 kg
Axle bore Ø (d)	15 mm
Hub length (T1)	45 mm
Unit weight	0.151 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

