

EA986MB- 150




EAN: 4047526005504

ID: 5504

Nylon wheel

Tyre & running tread: Made of high-quality, impact-resistant nylon. Tread colour: natural white
Rim / wheel centre: -

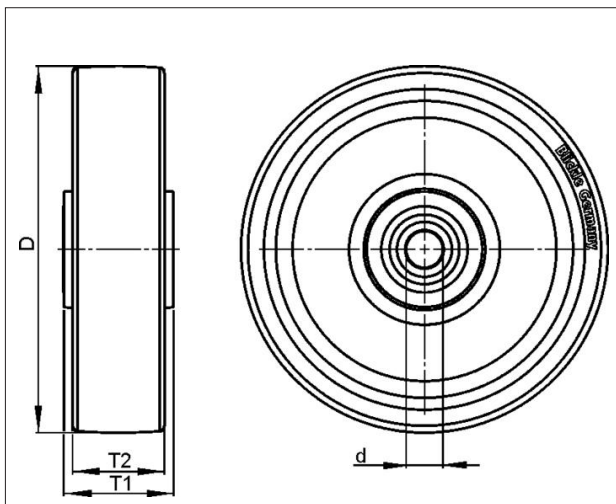

Technical data

Wheel Ø (D)	150 mm
Wheel width (T2)	50 mm
Load capacity	400 kg
Axle bore Ø (d)	20 mm
Hub length (T1)	60 mm
Unit weight	0.391 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

