


## EA986MB-5

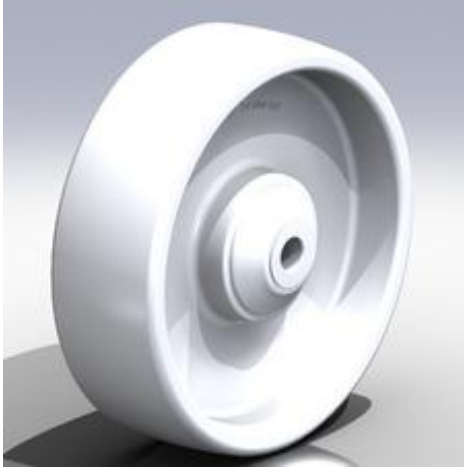


**EAN:** 4047526545109

**ID:** 545103

**Nylon wheel**

**Tyre & running tread:** Made of high-quality, impact-resistant nylon. Tread colour: natural white  
**Rim / wheel centre:** -

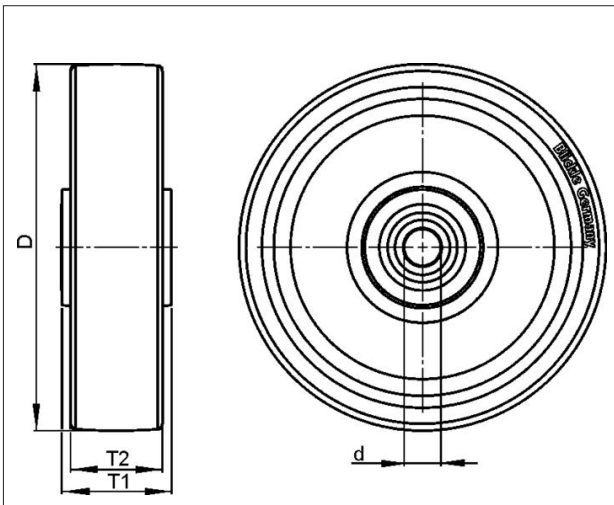

### Technical data

Wheel Ø (D)	125 mm
Wheel width (T2)	40 mm
Load capacity	300 kg
Axle bore Ø (d)	10 mm
Hub length (T1)	46 mm
Unit weight	0.273 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise




Floor surface preservation



**PO 125/10K**

Variants

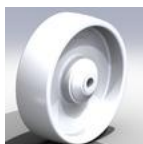

Wheel with  
additional ball bearing  
seals