

## EA986MB- 75




**EAN: 4047526005436**

**ID: 5439**

**Nylon wheel**

**Tyre & running tread:** Made of high-quality, impact-resistant nylon. Tread colour: natural white  
**Rim / wheel centre:** -

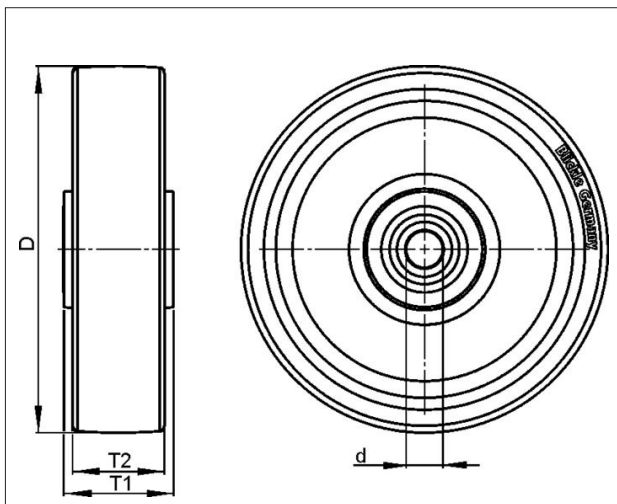

### Technical data

Wheel Ø (D)	75 mm
Wheel width (T2)	32 mm
Load capacity	200 kg
Axle bore Ø (d)	12 mm
Hub length (T1)	35 mm
Unit weight	0.077 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



**Blickle Räder+Rollen GmbH u. Co. KG**

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany  
 Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209  
 E-Mail: [info@blickle.com](mailto:info@blickle.com) · Internet: [www.blickle.com](http://www.blickle.com)

© Blickle Räder+Rollen GmbH u. Co. KG 2013  
 Rosenfeld · Germany