

EA986MB- 8




EAN: 4047526005580

ID: 5587

Nylon wheel

Tyre & running tread: Made of high-quality, impact-resistant nylon. Tread colour: natural white
Rim / wheel centre: -

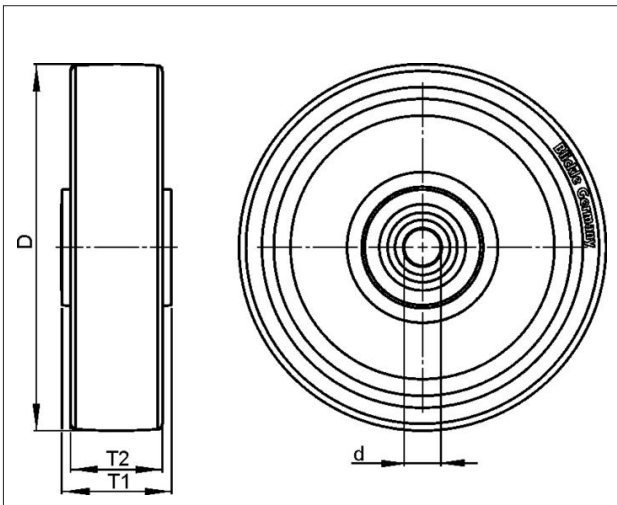

Technical data

Wheel Ø (D)	200 mm
Wheel width (T2)	50 mm
Load capacity	600 kg
Axle bore Ø (d)	20 mm
Hub length (T1)	60 mm
Unit weight	0.958 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

