

EA986MC-100




EAN: 4047526029128

ID: 29124

Wheel with standard solid rubber tyres, with synthetic rim

Tyre & running tread: Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC. Tread colour: black

Rim / wheel centre: Made of high-quality, impact-resistant polypropylene. Pressed-on tyre.

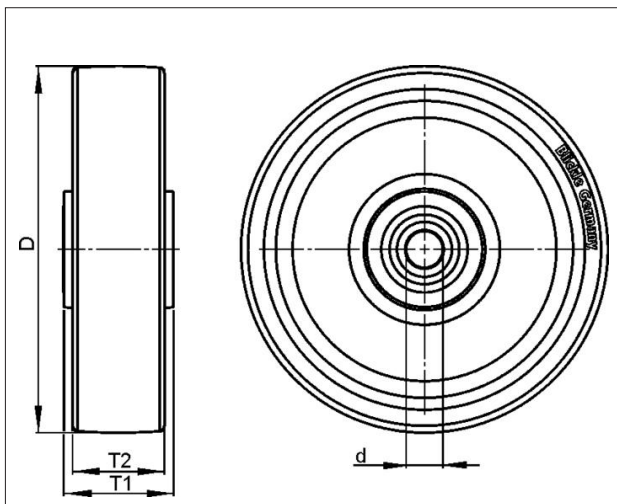

Technical data

Wheel Ø (D)	100 mm
Wheel width (T2)	30 mm
Load capacity	70 kg
Axle bore Ø (d)	15 mm
Hub length (T1)	45 mm
Unit weight	0.183 kg
Temperature range from	-20 °C
Temperature range to	60 °C
Tread & tyre hardness	80° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



VPP 100/15G

Variants



With non-marking grey
tyre