

EA986MC-180




EAN: 4047526013110

ID: 13110

Wheel with standard solid rubber tyres, with synthetic rim

Tyre & running tread: Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC. Tread colour: black

Rim / wheel centre: Made of high-quality, impact-resistant polypropylene. Pressed-on tyre.

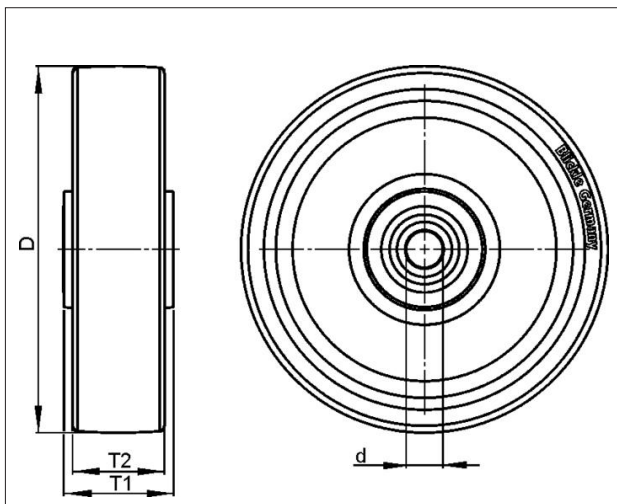

Technical data

| | |
|------------------------|-------------|
| Wheel Ø (D) | 180 mm |
| Wheel width (T2) | 50 mm |
| Load capacity | 170 kg |
| Axle bore Ø (d) | 20 mm |
| Hub length (T1) | 60 mm |
| Unit weight | 0.872 kg |
| Temperature range from | -20 °C |
| Temperature range to | 60 °C |
| Tread & tyre hardness | 80° Shore A |
| Bearing type | |

| | |
|----------------------------|--|
| Rolling resistance | <input checked="" type="checkbox"/> <input checked="" type="checkbox"/> <input type="checkbox"/> <input type="checkbox"/> <input type="checkbox"/> |
| Operating noise | <input checked="" type="checkbox"/> <input checked="" type="checkbox"/> <input checked="" type="checkbox"/> <input checked="" type="checkbox"/> <input type="checkbox"/> |
| Floor surface preservation | <input checked="" type="checkbox"/> <input checked="" type="checkbox"/> <input checked="" type="checkbox"/> <input checked="" type="checkbox"/> <input type="checkbox"/> |

Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany
 Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209
 E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
 Rosenfeld · Germany

VPP 180/20G

Variants



With non-marking grey
tyre