

EA986MC- 3




EAN: 4047526033026

ID: 33027

Wheel with standard solid rubber tyres, with synthetic rim

Tyre & running tread: Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC. Tread colour: black


Rim / wheel centre: Made of high-quality, impact-resistant polypropylene. Pressed-on tyre.

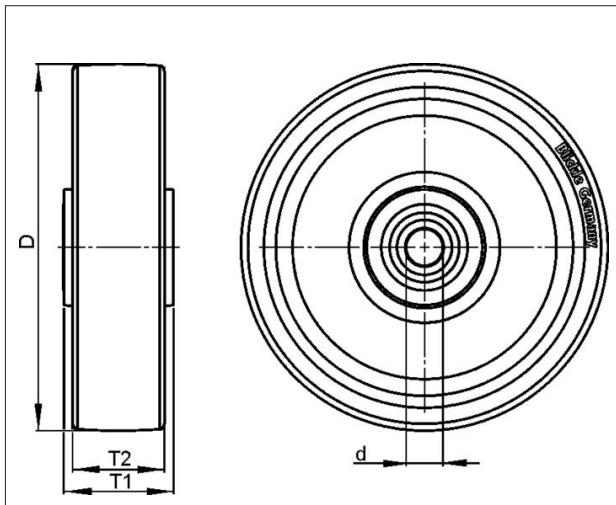

Technical data

Wheel Ø (D)	125 mm
Wheel width (T2)	37,5 mm
Load capacity	100 kg
Axle bore Ø (d)	15 mm
Hub length (T1)	45 mm
Unit weight	0.394 kg
Temperature range from	-20 °C
Temperature range to	60 °C
Tread & tyre hardness	80° Shore A
Bearing type	

 Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany

Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209

E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
Rosenfeld · Germany

VPP 125/15R

Variants



With non-marking grey
tyre