

EA986MC-9




EAN: 4047526034429

ID: 34421

Wheel with standard solid rubber tyres, with synthetic rim

Tyre & running tread: Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC. Tread colour: black

Rim / wheel centre: Made of high-quality, impact-resistant polypropylene. Pressed-on tyre.

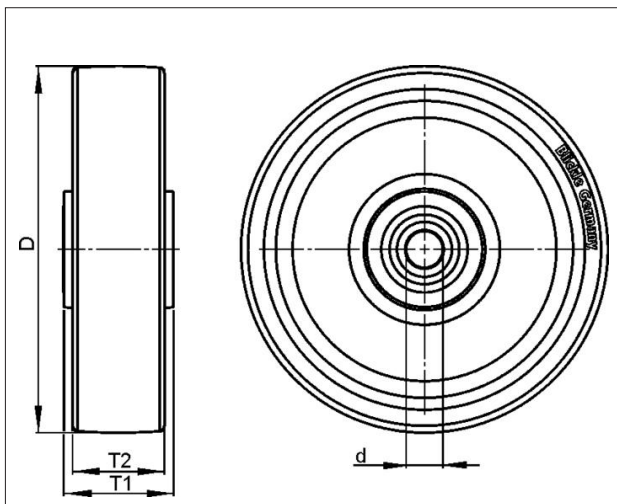

Technical data

Wheel Ø (D)	250 mm
Wheel width (T2)	60 mm
Load capacity	295 kg
Axle bore Ø (d)	25 mm
Hub length (T1)	65 mm
Unit weight	2.126 kg
Temperature range from	-20 °C
Temperature range to	60 °C
Tread & tyre hardness	80° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



VPP 250/25R

Variants



With non-marking grey
tyre