

EA986MD- 125




EAN: 4047526006921

ID: 6924

Heavy duty nylon wheel

Tyre & running tread: Made of high-quality, impact-resistant nylon, very rugged, heavy wheel design, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance.
Tread colour: natural white

Rim / wheel centre: -

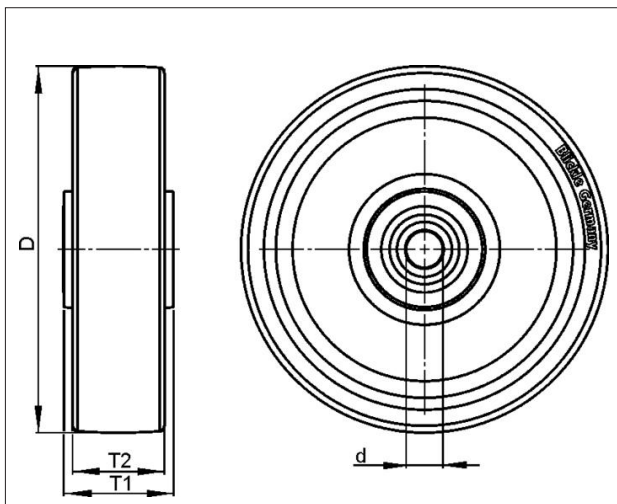

Technical data

Wheel Ø (D)	125 mm
Wheel width (T2)	40 mm
Load capacity	700 kg
Axle bore Ø (d)	15 mm
Hub length (T1)	45 mm
Unit weight	0.391 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

