

EA986ME- 4




EAN: 4047526253608

ID: 253609

Wheel with thermoplastic polyurethane tread, with heavy nylon wheel centre

Tyre & running tread: Made of high-quality thermoplastic polyurethane, high operational comfort, low-noise operation, low rolling and swivelling resistance, good floor preservation, very high abrasion resistance, chemically bonded for an inseparable connection to the wheel centre. Tread colour: dark grey

Rim / wheel centre: Made of high-quality, impact-resistant nylon.

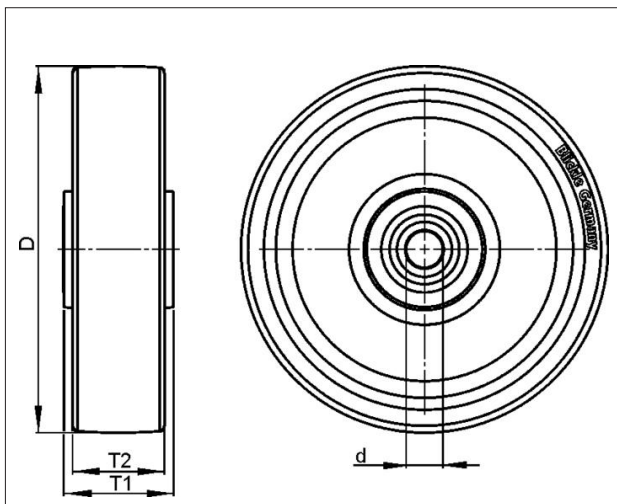

Technical data

Wheel Ø (D)	100 mm
Wheel width (T2)	35 mm
Load capacity	300 kg
Axle bore Ø (d)	10 mm
Hub length (T1)	46 mm
Unit weight	0.238 kg
Temperature range from	-25 °C
Temperature range to	70 °C
Tread & tyre hardness	94° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



POTH 100/10K

Variants



Wheel with
additional ball bearing
seals