

EA986MG- 160




EAN: 4047526041007

ID: 41004

Wheel with standard solid rubber tyres, with pressed steel rim, reinforced design

Tyre & running tread: Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC. Tread colour: black

Rim / wheel centre: Pressed steel rim with tubular steel hub, bolted, zinc-plated, blue-passivated, Cr6-free.

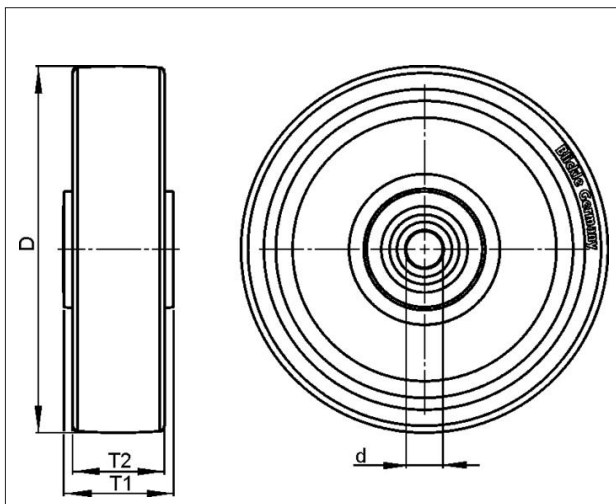

Technical data

Wheel Ø (D)	160 mm
Wheel width (T2)	40 mm
Load capacity	135 kg
Axle bore Ø (d)	20 mm
Hub length (T1)	60 mm
Unit weight	1.221 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	80° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



V 162/20R

Variants	
	Antistatic version
	With non-marking grey tyre