

EA986MG- 250




EAN: 4047526041182

ID: 41186

Wheel with standard solid rubber tyres, with pressed steel rim

Tyre & running tread: Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC. Tread colour: black

Rim / wheel centre: Pressed steel rim with tubular steel hub, pressed rim (special shock and impact-resistant design), zinc-plated, blue-passivated, Cr6-free. Tyre pressed with rim.

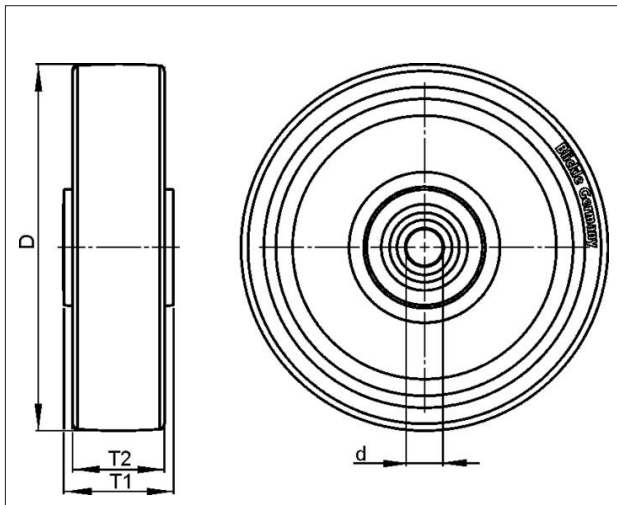

Technical data

Wheel Ø (D)	250 mm
Wheel width (T2)	60 mm
Load capacity	295 kg
Axle bore Ø (d)	25 mm
Hub length (T1)	65 mm
Unit weight	3.487 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	80° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



V 252/25R

Variants	
	Antistatic version
	With non-marking grey tyre