

EA986MH- 160




EAN: 4047526003449

ID: 3442

Heavy duty wheel with elastic solid rubber tyres 'Blickle EasyRoll', with welded steel wheel centre

Tyre & running tread: Made of high-quality elastic solid rubber, in smooth rolling quality "Blickle EasyRoll", very high operational comfort, low-noise operation, low rolling resistance, very good floor preservation, vulcanised on the wheel centre. Tread colour: black

Rim / wheel centre: Pressed thick-walled steel, triple-welded, with tubular steel hub, lacquered. Vulcanised tyre.

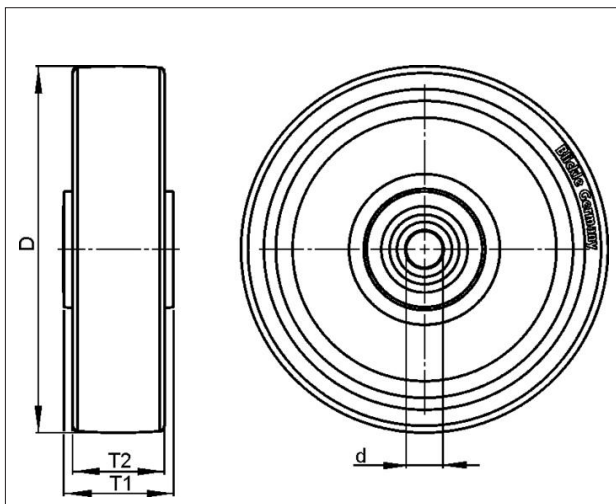

Technical data

Wheel Ø (D)	160 mm
Wheel width (T2)	50 mm
Load cap. with 4 km/h	450 kg
Load cap. with 10 km/h	250 kg
Axle bore Ø (d)	20 mm
Hub length (T1)	60 mm
Unit weight	1.568 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	65° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany

Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209

E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
Rosenfeld · Germany

SE 160/20K

Variants



With non-marking grey
tyre