

EA986MH- 250




EAN: 4047526003470

ID: 3475

Heavy duty wheel with elastic solid rubber tyres 'Blickle EasyRoll', with welded steel wheel centre

Tyre & running tread: Made of high-quality elastic solid rubber, in smooth rolling quality "Blickle EasyRoll", very high operational comfort, low-noise operation, low rolling resistance, very good floor preservation, vulcanised on the wheel centre. Tread colour: black

Rim / wheel centre: Pressed thick-walled steel, triple-welded, with tubular steel hub, lacquered. Vulcanised tyre.

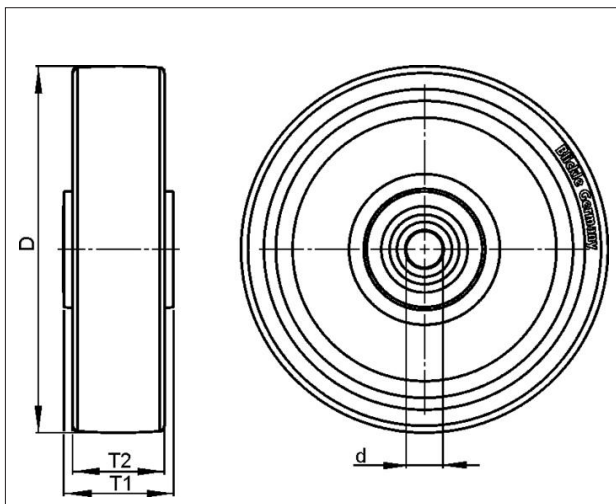

Technical data

Wheel Ø (D)	250 mm
Wheel width (T2)	60 mm
Load cap. with 4 km/h	850 kg
Load cap. with 10 km/h	500 kg
Axle bore Ø (d)	25 mm
Hub length (T1)	70 mm
Unit weight	3.631 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	65° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

