

EA986MK- 150




EAN: 4047526267438

ID: 267435

Heat-resistant Blickle TempLine® Classic thermoset wheel

Tyre & running tread: Made of phenolic resin, very high static load capacity, smooth running performance on even floors. Tread colour: black

Rim / wheel centre: -

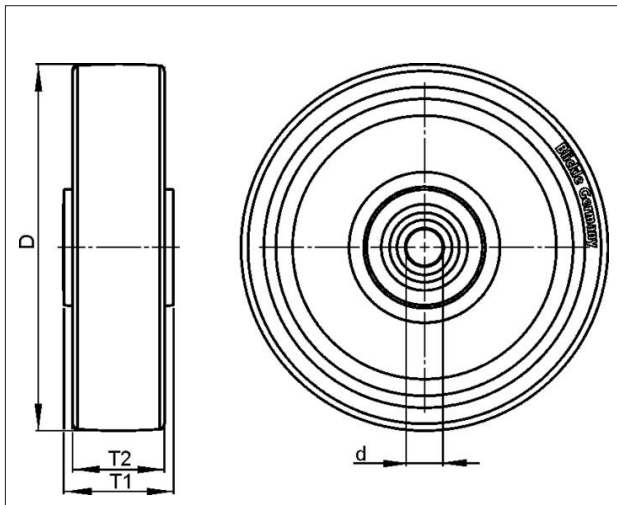

Technical data

Wheel Ø (D)	150 mm
Wheel width (T2)	50 mm
Load capacity	300 kg
Axle bore Ø (d)	20 mm
Hub length (T1)	60 mm
Unit weight	1.336 kg
Temperature range from	-35 °C
Temperature range to	260 °C
Tread & tyre hardness	90° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

