

Product Data Sheet



ALBS 100/15K

EAN 4047526000820

ID 740783

Heavy duty wheel with Blickle Besthane® Soft polyurethane tread, with aluminium wheel centre

Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Besthane® Soft, very high operational comfort through the especially thick, elastic tread, low-noise operation, very low rolling resistance, high dynamic load capacity, very good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre.

Tread/tyre:


Made of high-quality polyurethane-elastomer Blickle Besthane® Soft, very low rolling resistance, high dynamic load capacity.

Tread colours blue

Wheel centre/rim:

Made of die-cast aluminium. Casted tread.

Wheel centre colour: silver grey

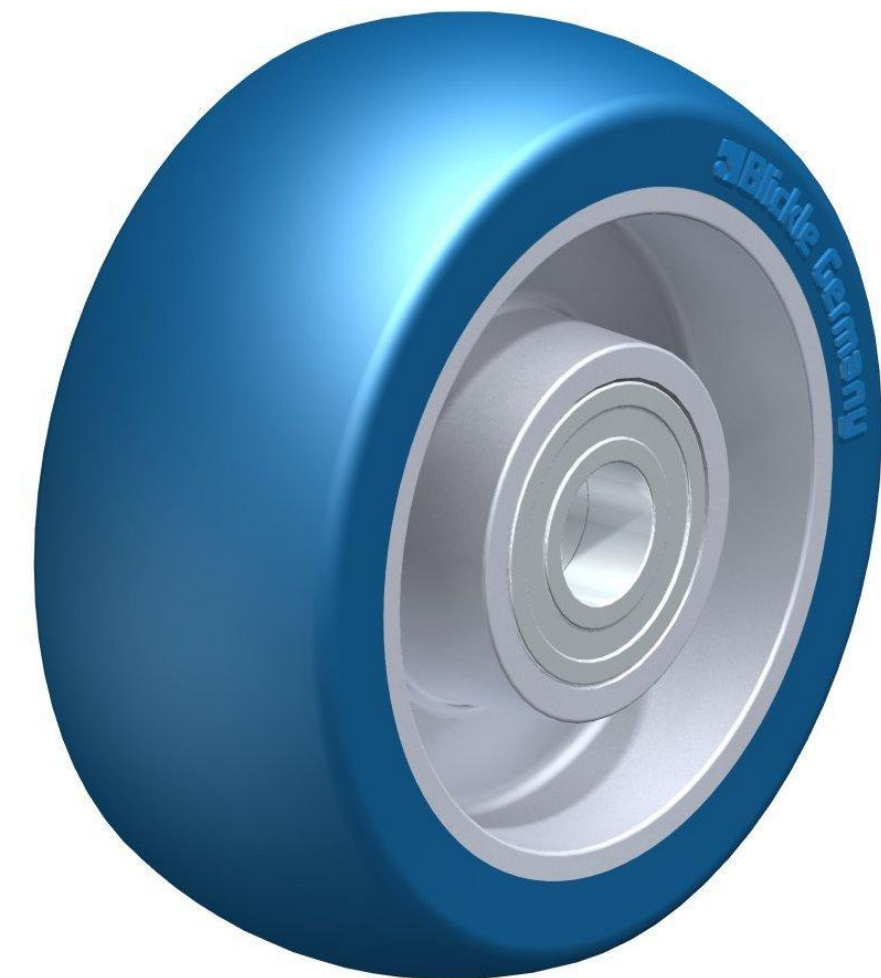

Rolling resistance

■■■■■ Excellent

Operating noise

■■■■□ Very good

Floor surface preservation

■■■■□ Very good

Technical data

Wheel Ø	⊘	100 mm (D)
Wheel width	⊥	40 mm (T2)
Load capacity	⚖	300 kg
Axle bore Ø	⊘	15 mm (d)
Hub length	⊥	40 mm (T1)
unit weight	⚖	0,4 kg
Temperature resistance	🔥	-25 ° C
Temperature resistance to	🔥	70 ° C
tread and tyre hardness		75° Shore A
Bearing type:	⊙	Ball bearing

