

# Product Data Sheet



## ALBS 125/15K

EAN 4047526000837

ID 740784

**Heavy duty wheel with Blickle Besthane® Soft polyurethane tread, with aluminium wheel centre**

### Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Besthane® Soft, very high operational comfort through the especially thick, elastic tread, low-noise operation, very low rolling resistance, high dynamic load capacity, very good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre.

### Tread/tyre:


Made of high-quality polyurethane-elastomer Blickle Besthane® Soft, very low rolling resistance, high dynamic load capacity.

**Tread colours** blue

### Wheel centre/rim:

Made of die-cast aluminium. Casted tread.

**Wheel centre colour:** silver grey

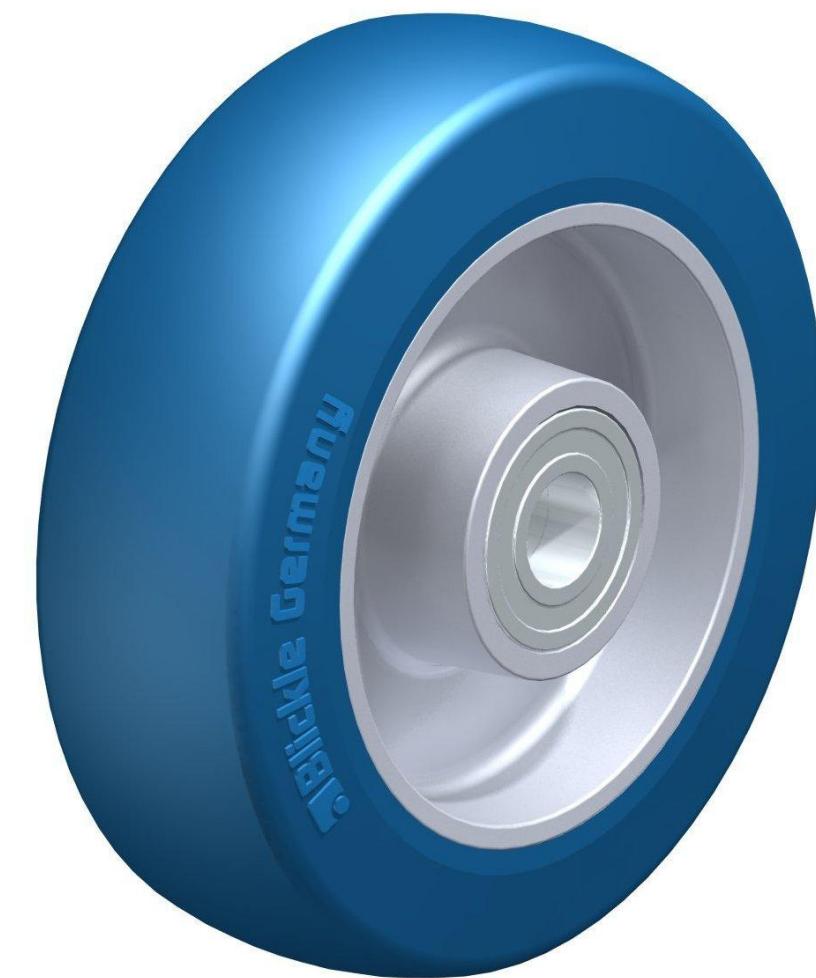

### Rolling resistance

■■■■■ Excellent

### Operating noise

■■■■■□ Very good

### Floor surface preservation

■■■■■□ Very good

### Technical data

Wheel Ø	⊘	125 mm (D)
Wheel width	⊥	40 mm (T2)
Load capacity	⚖	350 kg
Axle bore Ø	⊘	15 mm (d)
Hub length	⊥	45 mm (T1)
unit weight	⚖	0,6 kg
Temperature resistance	🔥	-25 ° C
Temperature resistance to	🔥	70 ° C
tread and tyre hardness		75° Shore A
Bearing type:	⊙	Ball bearing

