

## EA986MP- 150




**EAN: 4047526284510**

**ID: 284513**

**Heavy duty wheel with Blickle Extrathane® polyurethane tread, with aluminium wheel centre**

**Tyre & running tread:** Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre. Tread colour: light brown

**Rim / wheel centre:** Made of die-cast aluminium. Casted tread.

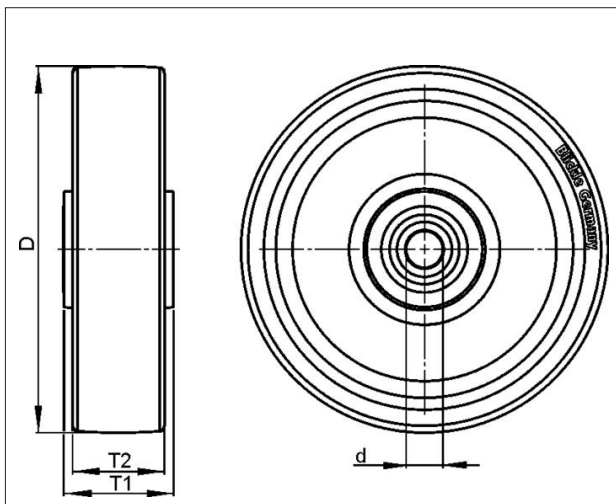

### Technical data

|                        |             |
|------------------------|-------------|
| Wheel Ø (D)            | 150 mm      |
| Wheel width (T2)       | 50 mm       |
| Load capacity          | 500 kg      |
| Axle bore Ø (d)        | 20 mm       |
| Hub length (T1)        | 60 mm       |
| Unit weight            | 1.013 kg    |
| Temperature range from | -25 °C      |
| Temperature range to   | 70 °C       |
| Tread & tyre hardness  | 92° Shore A |
| Bearing type           |             |

Rolling resistance



Operating noise



Floor surface preservation



**ALTH 150/20K**

Variants



Antistatic version, non-marking grey