

Product Data Sheet



PK 262/20-75G

EAN 4047526040673

ID 40675

Wheel with pneumatic tyres, with synthetic rim

Wheels:

Pneumatic tyre with tube, outstandingly high operational comfort, exceptionally high floor preservation, PAH conform acc. to EU directive 2005/69/EC.

Tread colours: black

Wheel centre/rim:

Made of high-quality, impact-resistant polypropylene. Tyre mounted on rim.

Wheel centre colour: black



Rolling resistance

■ ■ ■ □ □ Good

Operating noise

■ ■ ■ ■ ■ Excellent






 

 

 



Floor surface preservation


■ ■ ■ ■ ■ Excellent

Product Data Sheet



Technical data

Profile		Blockprofil
Wheel Ø		260 mm (D)
Tyre width		85 mm (T2)
Tyre dimension		3.00-4
Ply rating		2
Load capacity		150 kg
Tyre pressure		2,0/30 bar/psi
Axle bore Ø		20 mm (d)
Hub length		75 mm (T1)
Profile ribbed profile		B02
unit weight		1,1 kg
Temperature resistance		-20 ° C
Temperature resistance to		40 ° C
tread and tyre hardness		65° Shore A
Bearing type		Plain bore

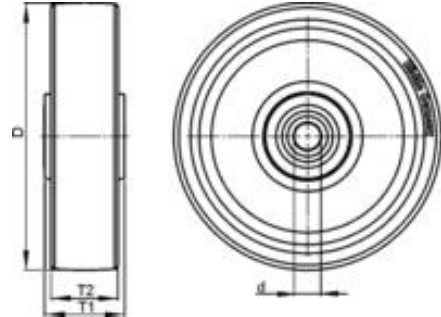

Product Data Sheet



Variants



PK 262/20-75G-SG

Wheel with pneumatic tyres, with synthetic rim



PK 262/20-75G-ROT

Wheel with pneumatic tyres, with synthetic rim



PK 262/20-75G-SG-ROT

Wheel with pneumatic tyres, with synthetic rim