

## Product Data Sheet



### PK 302/25-75G

EAN 4047526261375

ID 261370

#### Wheel with pneumatic tyres, with synthetic rim

##### Wheels:

Pneumatic tyre with tube, outstandingly high operational comfort, exceptionally high floor preservation, PAH conform acc. to EU directive 2005/69/EC.

**Tread colours:** black

##### Wheel centre/rim:

Made of high-quality, impact-resistant polypropylene. Tyre mounted on rim.

**Wheel centre colour:** black



##### Rolling resistance

■ ■ ■ □ □ Good

##### Operating noise

■ ■ ■ ■ ■ Excellent

##### Floor surface preservation


■ ■ ■ ■ ■ Excellent

# Product Data Sheet



## Technical data

Profile		Blockprofil
Wheel Ø		300 mm (D)
Tyre width		100 mm (T2)
Tyre dimension		4.00-4
Ply rating		2
Load capacity		180 kg
Tyre pressure		2,0/30 bar/psi
Axle bore Ø		25 mm (d)
Hub length		75 mm (T1)
Profile ribbed profile		B02
unit weight		1,5 kg
Temperature resistance		-20 ° C
Temperature resistance to		40 ° C
tread and tyre hardness		65° Shore A
Bearing type		Plain bore

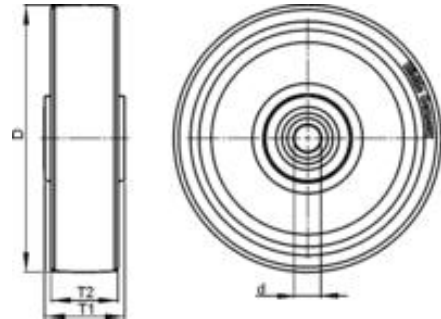

## Product Data Sheet



### Variants



**PK 302/25-75G-R0T**

Wheel with pneumatic tyres, with synthetic rim