

Product Data Sheet



LH-SVS 100K-1

EAN 4047526584832

ID 584839

Pressed steel swivel castor, heavy duty castors, with top plate fitting, Extra heavy duty solid steel wheel

Bracket:

Made of heavy pressed steel, with heavy fork and top plate, very strong bolted and secured central kingpin, double ball bearing in the swivel head, additionally reinforced by the integration of four specially shaped and hardened bearing seats resulting in a very high resistance to shock and impact loads. Bolted wheel axle. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Made of mild steel, with slightly crowned tread and lightly oiled surface, very low rolling and swivelling resistance, smooth running performance on even floors, extremely wear-resistant, particularly high static and dynamic load capacity.

Tread colours: silver

Wheel centre/rim: - Wheel centre colour: silver



Rolling resistance

■■■■■ Excellent

Operating noise

■□□□□ Sufficient

Floor surface preservation


■□□□□ Sufficient

Product Data Sheet



Technical data

Plate size		100 x 85
Bolt hole spacing		80 x 60
Bolt hole Ø		9
Wheel Ø		100 mm (D)
Wheel width		40 mm (T2)
Load capacity		700 kg
Total height		140 mm (H)
Offset swivel castor		45 mm
unit weight		3,4 kg
Temperature resistance		-25 ° C
Temperature resistance to		120 ° C
tread and tyre hardness		190 - 230 HB
Bearing type		Ball bearing

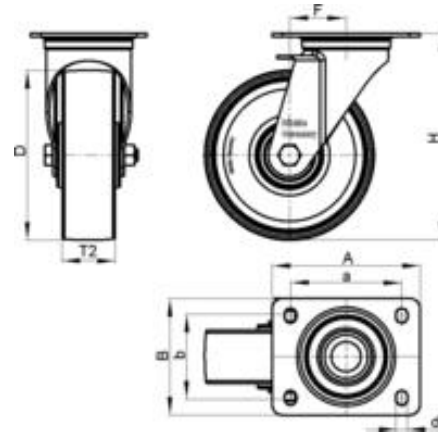

Product Data Sheet



Option:



RI-04.01

Directional lock