

# Product Data Sheet



## LH-SVS 127K

**EAN** 4047526584931

**ID** 584938

**Pressed steel swivel castor, heavy duty castors, with top plate fitting, Extra heavy duty solid steel wheel**

### Bracket:

Made of heavy pressed steel, with heavy fork and top plate, very strong bolted and secured central kingpin, double ball bearing in the swivel head, additionally reinforced by the integration of four specially shaped and hardened bearing seats resulting in a very high resistance to shock and impact loads. Bolted wheel axle. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

### Wheels:

Made of mild steel, with slightly crowned tread and lightly oiled surface, very low rolling and swivelling resistance, smooth running performance on even floors, extremely wear-resistant, particularly high static and dynamic load capacity.

**Tread colours:** silver

**Wheel centre/rim: - Wheel centre colour:** silver



### Rolling resistance

■■■■■ Excellent

### Operating noise

■□□□□ Sufficient

### Floor surface preservation


■□□□□ Sufficient

# Product Data Sheet



## Technical data

Plate size		140 x 110
Bolt hole spacing		105 x 75-80
Bolt hole Ø		11
Wheel Ø		125 mm (D)
Wheel width		55 mm (T2)
Load capacity		900 kg
Total height		170 mm (H)
Offset swivel castor		55 mm
unit weight		7 kg
Temperature resistance		-25 ° C
Temperature resistance to		120 ° C
tread and tyre hardness		190 - 230 HB
Bearing type		Ball bearing

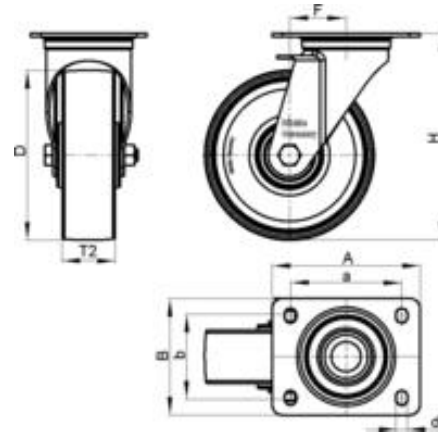

## Product Data Sheet



### Option:



**RI-05.03**

Directional lock