

# Product Data Sheet



## HTH 60X60/10-56K

EAN 4047526467111

ID 467118


**Rollers for pallet trucks with Blickle Extrathane® polyurethane tread, with steel wheel centre**

### Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low noise operation, low rolling resistance, good floor preservation, very high abrasion resist; high cut and tear propagation resistance, very good chemical connection with the wheel centre.

**Tread colours:** light brown

**Wheel centre/rim:** Made of steel or grey cast iron. **Wheel centre colour:** silver

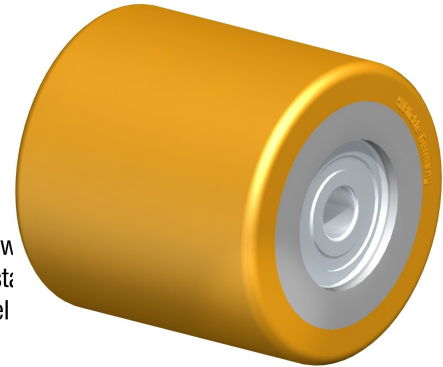

### Rolling resistance

■■■■■ □ Very good

### Operating noise

■■■■ □ □ Good

### Floor surface preservation

■■■■ □ □ Good

### Technical data

Wheel Ø		60 mm (D)
Wheel width		60 mm (T2)
Load capacity		320 kg
Axle bore Ø		10 mm (d)
Clamping length		56 mm (T5)
unit weight		0,5 kg
Temperature resistance		-25 ° C
Temperature resistance to tread and tyre hardness		70 ° C
tread and tyre hardness		92° Shore A
Bearing type		Ball bearing

