

# Product Data Sheet



## HTH 75X40/20-40K

EAN 4047526269616

ID 269613

**Rollers for pallet trucks with Blickle Extrathane® polyurethane tread, with steel wheel centre**


### Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre.

**Tread colours:** light brown

**Wheel centre/rim:** Made of steel or grey cast iron. **Wheel centre colour:**

silver

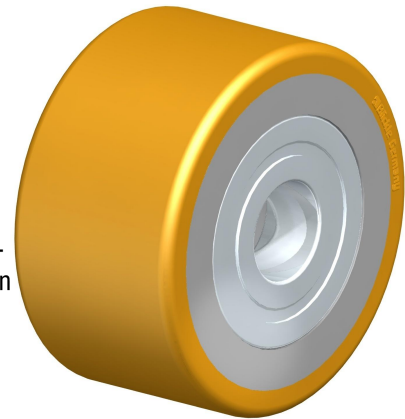

### Rolling resistance

■■■■□ Very good

### Operating noise

■■■■□ Good

### Floor surface preservation

■■■■□ Good

### Technical data

Wheel Ø		75 mm (D)
Wheel width		40 mm (T2)
Bearing seat depth		mm (t)
Load capacity		270 kg
Axle bore Ø		20 mm (d)
Clamping length		40 mm (T5)
unit weight		0,6 kg
Temperature resistance		-25 ° C
Temperature resistance to tread and tyre hardness		70 ° C
tread and tyre hardness		92° Shore A
Bearing type		Ball bearing

