

Product Data Sheet



HTH 75X75/20-75K

EAN 4047526467128

ID 467126

Rollers for pallet trucks with Blickle Extrathane® polyurethane tread, with steel wheel centre


Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low noise operation, low rolling resistance, good floor preservation, very high abrasion resist; high cut and tear propagation resistance, very good chemical connection with the wheel centre.

Tread colours: light brown

Wheel centre/rim: Made of steel or grey cast iron. **Wheel centre colour:**

silver

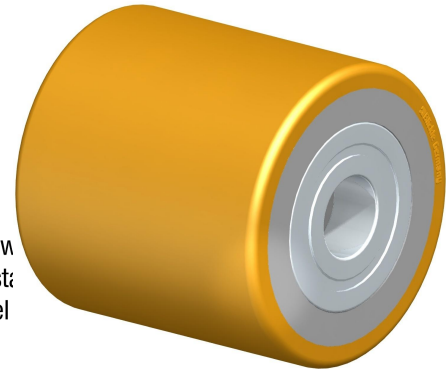

Rolling resistance

■■■■□ Very good

Operating noise

■■■■□□ Good

Floor surface preservation

■■■■□□ Good

Technical data

Wheel Ø		75 mm (D)
Wheel width		75 mm (T2)
Bearing seat depth		mm (t)
Load capacity		500 kg
Axle bore Ø		20 mm (d)
Clamping length		75 mm (T5)
unit weight		1 kg
Temperature resistance		-25 ° C
Temperature resistance to		70 ° C
tread and tyre hardness		92° Shore A
Bearing type		Ball bearing

