

Product Data Sheet



HTH 80X40/20-40K

EAN 4047526467159

ID 467159

Rollers for pallet trucks with Blickle Extrathane® polyurethane tread, with steel wheel centre


Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre.

Tread colours: light brown

Wheel centre/rim: Made of steel or grey cast iron. **Wheel centre colour:**

silver

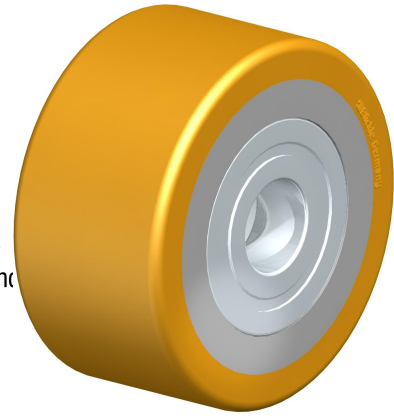

Rolling resistance

■■■■□ Very good

Operating noise

■■■■□ Good

Floor surface preservation

■■■■□ Good

Technical data

Wheel Ø		80 mm (D)
Wheel width		40 mm (T2)
Bearing seat depth		mm (t)
Load capacity		280 kg
Axle bore Ø		20 mm (d)
Clamping length		40 mm (T5)
unit weight		0,7 kg
Temperature resistance		-25 ° C
Temperature resistance to tread and tyre hardness		70 ° C
tread and tyre hardness		92° Shore A
Bearing type		Ball bearing

