

EA986RP-82B


EAN: 4047526269722

ID: 269720

Rollers for pallet trucks with Blickle Extrathane® polyurethane tread, with steel wheel centre



Tyre & running tread: Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre. Tread colour: light brown
Rim / wheel centre: Made of steel or grey cast iron.

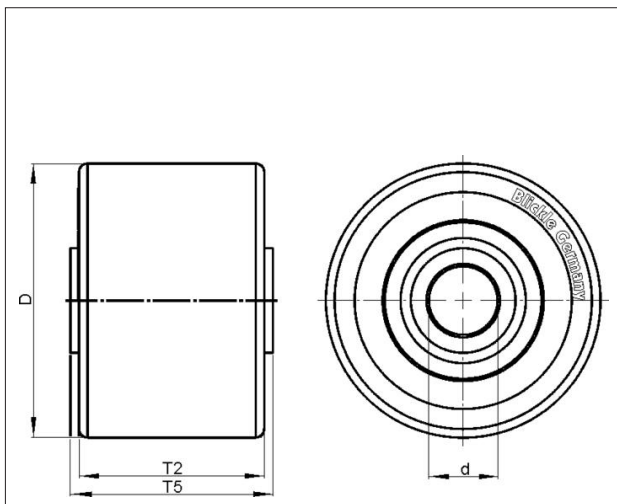

Technical data

Wheel Ø (D)	82 mm
Wheel width (T2)	98 mm
Load capacity	720 kg
Ball bearing	6204 ZZ
Bearing seat Ø (S)	0 mm
Bearing seat depth (t)	0 mm
Axle bore Ø (d)	20 mm
Clamping length (T5)	98 mm
Unit weight	1.45 kg
Temperature range from	-25 °C
Temperature range to	70 °C
Tread & tyre hardness	92° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

