

Product Data Sheet



HTH 85x120/25-124K

EAN 4047526710019

ID 710012


Rollers for pallet trucks with Blickle Extrathane® polyurethane tread, with steel wheel centre

Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre.

Tread colours: light brown

Wheel centre/rim: Made of steel or grey cast iron. **Wheel centre colour:** silver

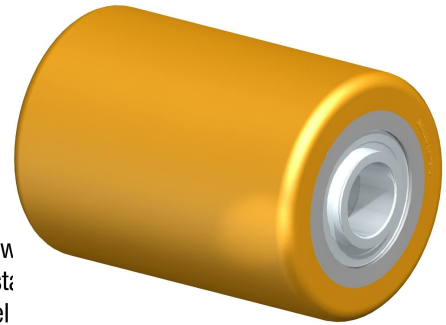

Rolling resistance

■■■■□ Very good

Operating noise

■■■■□ Good

Floor surface preservation

■■■■□ Good

Product Data Sheet



Technical data

Wheel Ø		85 mm (D)
Wheel width		120 mm (T2)
Load capacity		900 kg
Axle bore Ø		25 mm (d)
Clamping length		124 mm (T5)
Hub length		120 mm (T1)
unit weight		1,8 kg
Temperature resistance		-25 ° C
Temperature resistance to		70 ° C
tread and tyre hardness		92° Shore A
Bearing type		Ball bearing

