


EA986RW-17

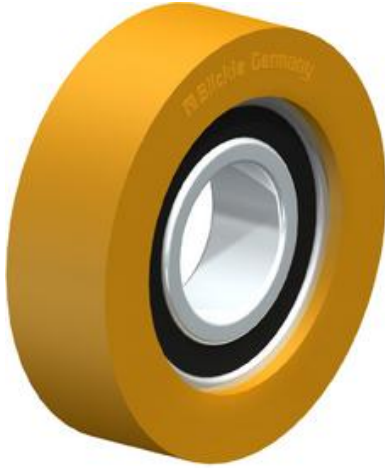


EAN: 4047526463885

ID: 463885

Guide roller with Blickle Extrathane® polyurethane tread

Tyre & running tread: Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, tread directly injected onto the ball bearing, very good chemical connection. Tread colour: light brown

Rim / wheel centre: -

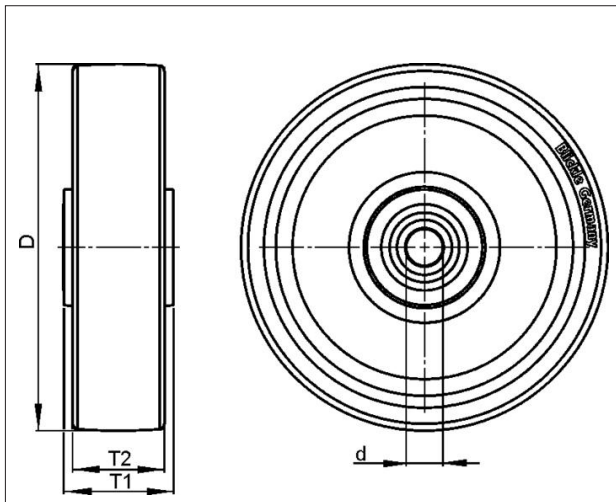

Technical data

Wheel Ø (D)	70 mm
Wheel width (T2)	20 mm
Load capacity	125 kg
Ball bearing	6205 2RS
Axle bore Ø (d)	25 mm
Clamping length (T5)	15 mm
Unit weight	0.17 kg
Temperature range from	-25 °C
Temperature range to	70 °C
Tread & tyre hardness	92° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

