


EA986RW-18

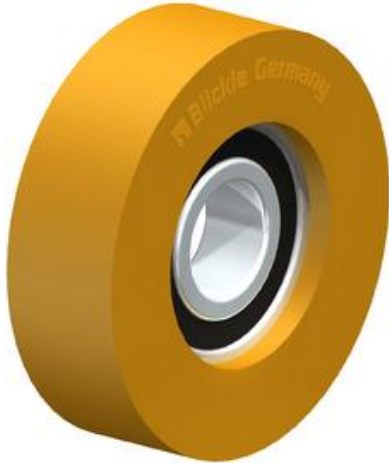


EAN: 4047526463892

ID: 463893

Guide roller with Blickle Extrathane® polyurethane tread

Tyre & running tread: Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, tread directly injected onto the ball bearing, very good chemical connection. Tread colour: light brown

Rim / wheel centre: -

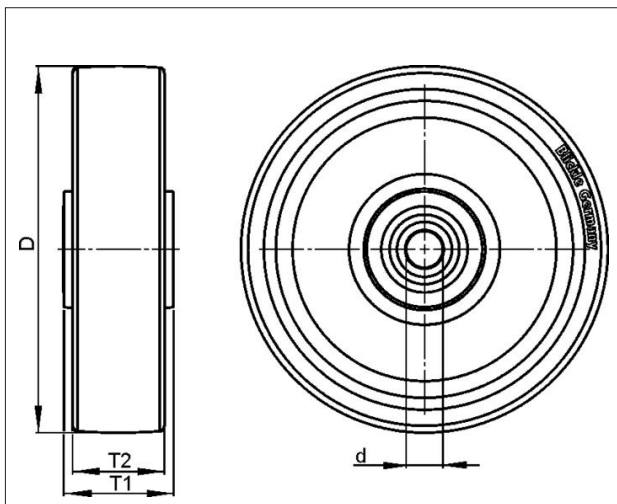

Technical data

Wheel Ø (D)	75 mm
Wheel width (T2)	23 mm
Load capacity	110 kg
Ball bearing	6204 2RS
Axle bore Ø (d)	20 mm
Clamping length (T5)	14 mm
Unit weight	0.176 kg
Temperature range from	-25 °C
Temperature range to	70 °C
Tread & tyre hardness	92° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany

Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209

E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
Rosenfeld · Germany