


## EA986RX-10

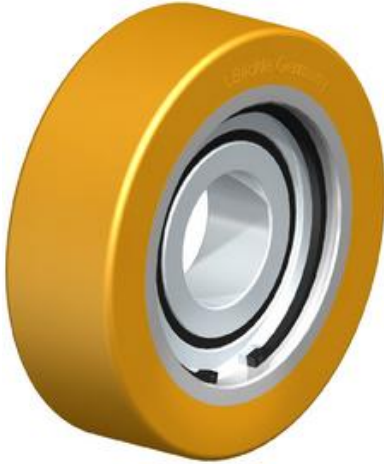


**EAN: 4047526463991**

**ID: 463992**

**Guide roller with Blickle Extrathane® polyurethane tread, with steel wheel centre**

**Tyre & running tread:** Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre. Tread colour: light brown

**Rim / wheel centre:** Made of steel. Casted tread.

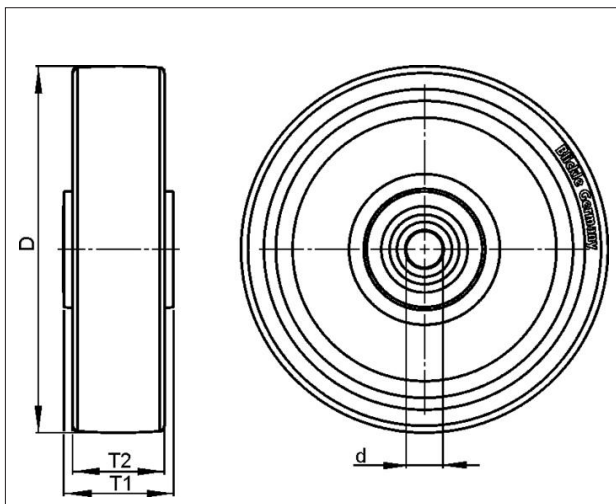

### Technical data

|                        |             |
|------------------------|-------------|
| Wheel Ø (D)            | 80 mm       |
| Wheel width (T2)       | 25 mm       |
| Load capacity          | 180 kg      |
| Ball bearing           | 6205 2RS    |
| Axle bore Ø (d)        | 25 mm       |
| Clamping length (T5)   | 15 mm       |
| Unit weight            | 0.341 kg    |
| Temperature range from | -25 °C      |
| Temperature range to   | 70 °C       |
| Tread & tyre hardness  | 92° Shore A |
| Bearing type           |             |

Rolling resistance



Operating noise



Floor surface preservation

