


EA986RX-12

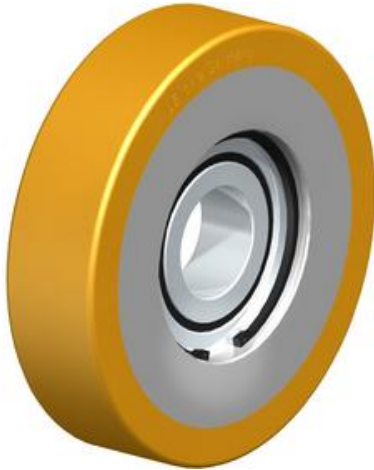


EAN: 4047526464011

ID: 464016

Guide roller with Blickle Extrathane® polyurethane tread, with steel wheel centre

Tyre & running tread: Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre. Tread colour: light brown

Rim / wheel centre: Made of steel. Casted tread.

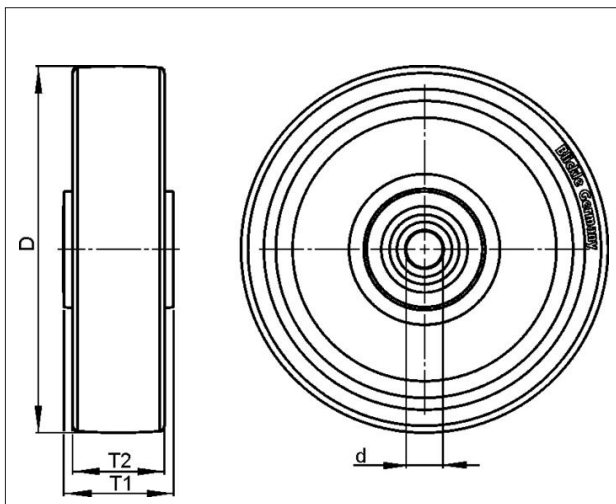

Technical data

Wheel Ø (D)	100 mm
Wheel width (T2)	25 mm
Load capacity	220 kg
Ball bearing	6205 2RS
Axle bore Ø (d)	25 mm
Clamping length (T5)	15 mm
Unit weight	0.847 kg
Temperature range from	-25 °C
Temperature range to	70 °C
Tread & tyre hardness	92° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

