


EA986RX-5

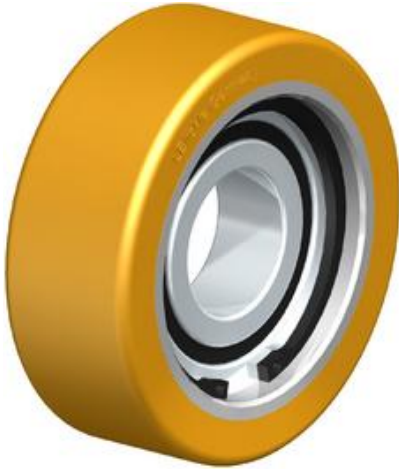


EAN: 4047526463953

ID: 463950

Guide roller with Blickle Extrathane® polyurethane tread, with steel wheel centre

Tyre & running tread: Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre. Tread colour: light brown

Rim / wheel centre: Made of steel. Casted tread.

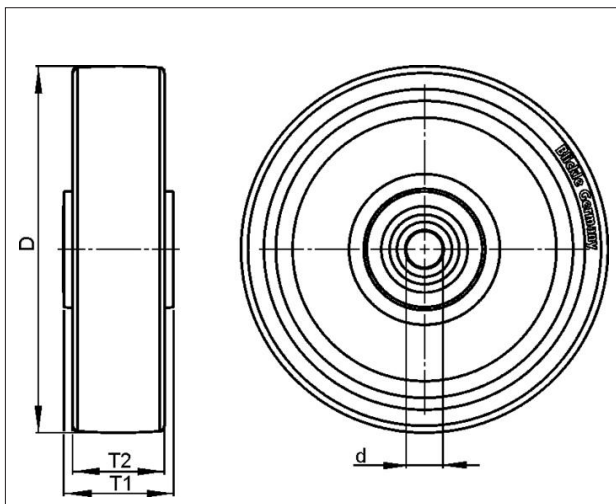

Technical data

Wheel Ø (D)	50 mm
Wheel width (T2)	18 mm
Load capacity	80 kg
Ball bearing	6003 2RS
Axle bore Ø (d)	17 mm
Clamping length (T5)	10 mm
Unit weight	0.103 kg
Temperature range from	-25 °C
Temperature range to	70 °C
Tread & tyre hardness	92° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

