


Sling hook 315

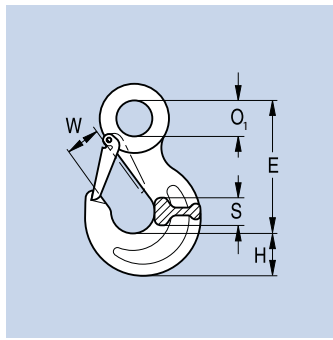


WLL kg	Weight approx. kg	Dimensions in mm					Reference no.
		E	H	O	S	W	
1120	0,25	85	20	20	16	20	112624
2000	0,59	117	28	28	21	27	112635
3150	1,18	157	30	36	24	36	112636
5300	2,13	186	43	46	30	38	112637
8000	3,88	227	52	56	38	48	112638

Safety hook with swivel eye

Painted version.

Application note: for positioning only,
but not for rotation under load.

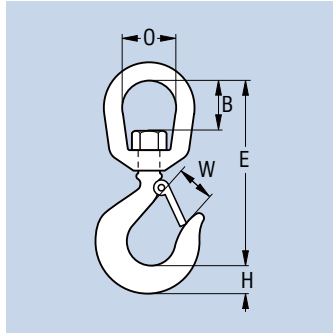

WLL kg	Weight approx. kg	Dimensions in mm					Reference no.
		B	E	H	O	W	
1250	0,43	28	116	20	31	22	110884
1600	0,85	36	145	22	40	23	110886
2500	1,40	49	165	26	47	25	110888
3200	1,51	45	175	29	47	28	110890
5400	3,70	55	214	37	64	34	110892
8000	6,60	70	264	46	78	43	110894
11500	10,25	74	308	58	90	53	110896
16000	15,80	86	344	67	96	58	110898
22000	26,00	114	427	78	122	80	110900
30000	60,00	125	505	99	135	95	110902

EA987GG-1

EA987GG-2

EA987GG-3

EA987GG-4


EA987GG-5

EA987GG-6

Sliding choker hook with safety latch

Red painted version, hook safety latch
galvanised.

Sliding hooks are particularly suitable
for bundling, for example for loads such
as bar goods, pipes, sacks, boards,
timber etc.

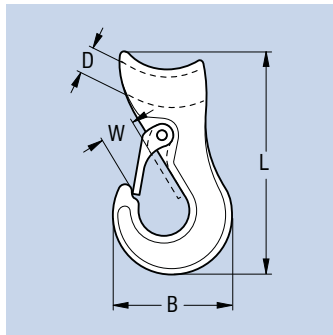

WLL kg	for nominal rope Ø mm	Weight approx. kg	Dimensions in mm				Reference no.
			B	D	L	W	
1250	Ø9-Ø13	0,7	70	17	128	19	112697
2000	Ø14-Ø16	1,0	80	22	147	22	112700
3000	Ø17-Ø19	1,8	103	27	174	30	112703
5000	Ø20-Ø26	3,4	133	33	210	40	112706

Working load limit identification tag For wire rope slings



for wire rope slings	Reference no.
1-leg	110196
multi-leg	110198

Thimbles

(see pages 224 – 225)



Shackle

(see pages 226 – 227)

