

Heavy Duty & Smooth Operation

EZ LEVER PUMP



320CC
per
Stroke

Smooth and easy strokes
Reinforced lightweight plastic construction

Specification

- Delivery volume: about 320cc per stroke
- Suction pipe length: 350mm to 985mm
- Suction end OD: 20mm
- Applicable liquids: Motor Oil, Hydraulic Oil, Lubricants, DEF(AdBlue), Non-potable Water, Windshield Washer Fluid, Antifreeze, Agricultural Chemicals

DLP-2105S



SPOUT




Recommended for Motor Oil,
Hydraulic Oil, Lubricants

- Spout OD: 20.6mm

DLP-2105H



PE HOSE
+
CLIP

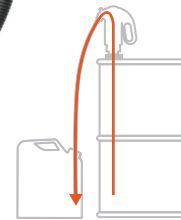


Recommended for Non-potable Water,
Windshield Washer Fluid, Antifreeze,
Agricultural Chemicals

- Discharge hose length: about 2m

DLP-2105N



PVC HOSE
+
NOZZLE

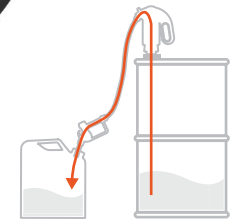

Recommended for DEF(AdBlue)

- Discharge hose length: about 2m
- Nozzle spout OD: 18mm (3/4")

MANUAL LEVER PUMP

Heavy Duty & Smooth Operation

Professional Pumping Systems
DUKSHIN

DLP-2105S


Specification

- Manual up and down piston lever pump
- Delivery volume: about 320cc per stroke
- Applicable liquids: Motor Oil, Hydraulic Oil, Lubricants, DEF(AdBlue), Antifreeze, Windshield Washer Fluid
- Reinforced lightweight plastic construction




3 Lever Handle

- Sturdy grip with ergonomic design
- Convenient and smooth lever operation (Max. 80°)
- Discharges about 320cc per stroke
- Operates smoothly with minimum force

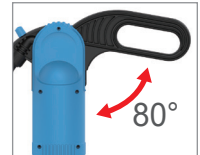

4 Double Blades Piston

- Piston designed with double blades
- Improved suction performance with air tight design

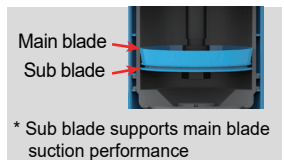


5 Drum Bung Adapter

- Improved grip of drum bung adapter - 60mm (2.4") wide grip makes it easy to tighten and loosen
- Pump head can be fixed in any direction on drum bung adapter making it convenient to use lever handle



※ 2" NPT to 2" buttress adapter(2.5x5) / trisure adapter(2.2x4) / mauser adapter(2.7x6) - Optional parts

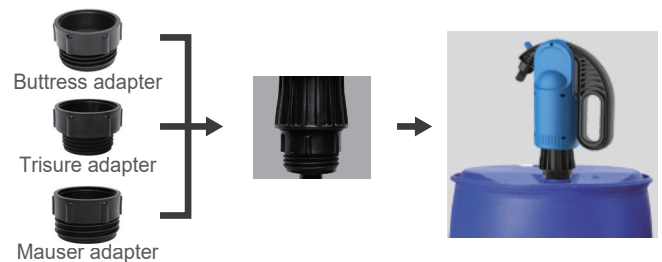

6 Telescopic Suction Pipe

- Three-piece telescopic suction pipe is adjustable from 350mm to 985mm to fit most containers
- Suction end outer diameter: 20mm



1 Air Vent Cap

- Turn clockwise and keep closed when used with spout
- Air vent cap can be opened to break siphon flow when used with hose



2 Spout

- Liquid can be easily dispensed into a jug
- 3/4" inner diameter hose can be attached to spout when liquid needs to be transferred to a different receiving tank



Professional Pumping Systems

DUKSHIN

Dukshin Corp., Ltd.
www.dukshin.com

Made in Korea

MANUAL LEVER PUMP

Heavy Duty & Smooth Operation

Professional Pumping Systems
DUKSHIN

DLP-2105H


Specification

- Manual up and down piston lever pump
- Delivery volume: about 320cc per stroke
- Discharge hose length: about 2 meter
- Applicable liquids: DEF(AdBlue), Non-potable Water, Windshield Washer Fluid, Antifreeze, Agricultural Chemicals, Lubricants
- Reinforced lightweight plastic construction



4 Double blades piston

- Piston designed with double blades
- Improved suction performance with air tight design

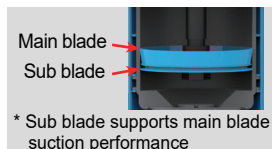


5 Drum bung adapter

- Improved grip of drum bung adapter - 60mm (2.4") wide grip makes it easy to tighten and loosen
- Pump head can be fixed in any direction on drum bung adapter making it convenient to use lever handle



※ 2" NPT to 2" buttress adapter(2.5x5) / trisure adapter(2.2x4) / mauser adapter(2.7x6) - Optional parts

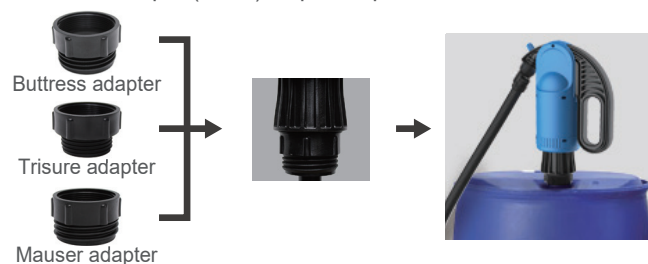

6 Telescopic suction pipe

- Three-piece telescopic suction pipe is adjustable from 350mm to 985mm to fit most containers
- Suction end outer diameter: 20mm



7 Discharge hose

- Flexible discharge hose allows high flow speed and easy handling
- Discharge hose length: about 2 meter
- Discharge hose end outer diameter: 20mm
- Hose is replaceable with regular 19mm inner diameter hose
- Option: manual nozzle

 
8 Discharge hose clip (Option)

- Discharge hose spout is attachable to receiving container
- Clip is adjustable along the length of spout



1 Air vent cap

- Quick & easy stop with durable air vent cap
- Turn clockwise before use and counter clockwise to stop flow




2 Hose clamp with hose holder

- Secure hose clamp with pump outlet
- Discharge hose can be kept safely and conveniently with swivel connection hose holder



3 Lever handle

- Sturdy grip with ergonomic design
- Convenient and smooth lever operation (Max. 80°)
- Discharges about 320cc per stroke
- Operates smoothly with minimum force

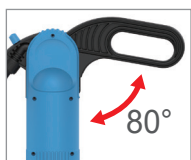

Professional Pumping Systems

DUKSHIN

Dukshin Corp., Ltd.
www.dukshin.com

Made in Korea

EZ LEVER PUMP

Heavy Duty & Smooth Operation

Professional Pumping Systems
DUKSHIN

DLP-2105N

 
Specification

- Manual up and down piston lever pump
- Delivery volume: about 320cc per stroke
- Self-priming
- Applicable liquids: DEF(AdBlue), non-potable water, windshield washer fluid, antifreeze, agricultural chemicals, lubricants
- Reinforced lightweight plastic construction




1 Air Vent Cap

- Quick & easy stop with durable air vent cap
- Turn clockwise before use and counter clockwise to stop flow




2 Lever Handle

- Sturdy grip with ergonomic design
- Convenient and smooth lever operation (Max. 80°)
- Discharges about 320cc per stroke
- Operates smoothly with minimum force

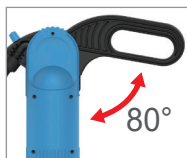

3 Double Blades Piston

- Piston designed with double blades
- Improved suction performance with air tight design

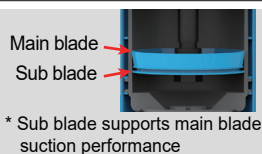


4 Drum Bung Adapter

- Improved grip of drum bung adapter - 60mm (2.4") wide grip makes it easy to tighten and loosen
- Pump head can be fixed in any direction on drum bung adapter making it convenient to use lever handle



※ 2" NPT to 2" buttress adapter (2.5x5) / trisure adapter (2.2x4) / mauser adapter (2.7x6) - Optional parts

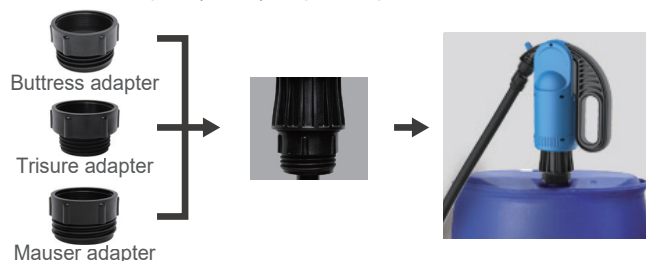

5 Telescopic Suction Pipe

- Three-piece telescopic suction pipe is adjustable from 350mm to 985mm to fit most containers
- Suction end outer diameter: 20mm



6 Two Types of Nozzle

- Plastic spout nozzle
- Stainless steel spout nozzle



Plastic spout
OD 25mm (1")



Stainless spout
OD 18mm (3/4")

※ Interchangeable with various kinds of discharge hoses
- Applicable inner diameter: 19mm (3/4")

7 Discharge Hose

- Guaranteed oil, fuel and cold weather resistance with high flexibility
- ISO 22241-2 certified
- Standard length: Approx. 2m (6.6ft)



Professional Pumping Systems

DUKSHIN

Dukshin Corp., Ltd.
www.dukshin.com

Made in Korea