

**12 VOLT**

# Cordless Rechargeable Grease Gun

The new Lincoln PowerLuber® 12 Volt Cordless Rechargeable Grease Gun is the most advanced grease gun ever created. Its powerful 12 volt motor delivers a consistent grease flow at up to 6000 psi for faster, more effective lubrication than manual methods. Its fully rechargeable power pack gives you unrestricted mobility.

PowerLuber's balanced design makes lubing hard-to-reach fittings routine. And when you've got a lot of fittings to hit, the rechargeable 12 volt battery provides long-lasting performance. Three-way loading makes refilling a snap.

There are three PowerLuber models, with a full range of accessories, designed to meet the demands of any lube application—from the professional mechanic to the do-it-yourselfer.

Discover how easy lubrication can be with the new Lincoln PowerLuber Grease Gun. Because with PowerLuber, you really can *grease anything, anytime, anywhere.*



## PowerLuber Pack and Accessories

### Model 1242

The standard PowerLuber Model 1242 comes outfitted with a heavy-duty carrying case designed to withstand even the harshest punishment.

Comes complete with:

- 110 volt fast charger (Model 1210)
- One 12 volt NiCad rechargeable battery (Model 1201)
- 30" flex hose with spring guard (Model 1230)
- Custom carrying case designed to hold optional rechargeable battery and two optional grease cartridges (grease not included)
- Patent pending

### Model 1244

Top of the line. The 1244 has everything for the serious professional including a second rechargeable battery.

### Model 1240


The 1240 is economy packed without the custom carrying case. Includes battery charger and one rechargeable battery.

## Features & Benefits

- ◆ Powerful 12 volt motor
- ◆ Planetary gear drive
- ◆ High-capacity 12 volt NiCad battery
- ◆ Machined and hardened piston
- ◆ 2" final drive needle bearings
- ◆ Plated steel barrel with exclusive flip-over follower
- ◆ Locking follower rod
- ◆ Accessible check valve
- ◆ Bleeder valve
- ◆ Outlet opening 7/16" UNEF
- ◆ Threaded opening (1/8" NPT) for filler nipple (not included)

## Models 1240, 1242 & 1244 PowerLuber® Enhancements for 2002

- ◆ New Pressure Relief Valve identifies proper grease flow and alerts user to blocked fittings
- ◆ Pressure Relief Valve prevents motor overload
- ◆ Redesigned Battery Clips secure battery
- ◆ New CE approved wiring design eliminates voltage and magnetic leakage
- ◆ CE approved assembly
- ◆ to handle in even the most severe conditions

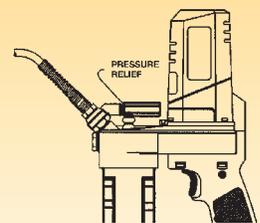

Now also available in 220 volt models for Europe and Latin America (Models 1242E and 1244E)