

Pistol Grip Grease Guns
All Weather

G70

G80

G85




All weather grease gun designed for convenient use even in very cold weather conditions

- Built Tough**
- Barrel with 0.049" (1.2 mm) wall thickness
 - Heavy duty follower spring
 - CNC machined aluminium die cast head with bulk loader valve that double as an air bleeder
 - Rolled threads for quick & easy re-loading
 - Heavy duty plunger spring keeps grease compressed and free of air pockets


Venturi Mechanism coupled with a large grease inlet helps retain prime

Also available with: **Unique Adjustable Mechanism** that switches between high pressure and high volume easily. High volume for faster greasing & high pressure for use in very cold weather conditions

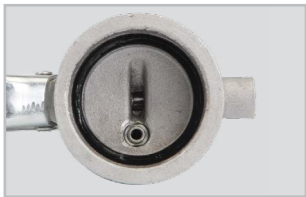

Grease Gun Head: Large grease inlet with venturi mechanism

FILLING OPTIONS

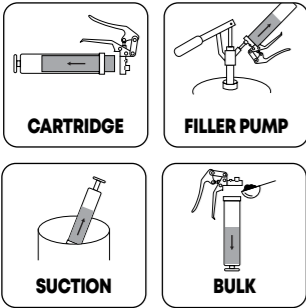

VARIANTS



G70

2-1/4"
(57.15 mm)

Use with 14 oz. (400 gms) grease cartridge / 500cc bulk fill

With double lipped follower for ease of use with cartridge or bulk grease without changeover

Comes with 18" (450mm) × 0.425" (11mm) high pressure grease hose & coupler



G80

2-1/4"
(57.15 mm)

Adjustable Mechanism

Use with 14 oz. (400 gms) grease cartridge / 500cc bulk fill

Comes with 12" (300mm) × 0.425" (11mm) high pressure grease hose & coupler



G85

63.5 mm

Adjustable Mechanism

Use with 450 gms. grease cartridge

Comes with 12" (300mm) × 0.425" (11 mm) high pressure grease hose & coupler



G70

Rugged die-cast handle

SPECIFICATIONS

DEVELOPS	UPTO 7,000 PSI	UPTO 483 BAR
DELIVERS	UPTO 1 OZ. / 40 STROKES	UPTO 0.68 GM / STROKE

ORDERING INFORMATION

CAT NR.	ORD NR.	CARTRIDGE CAPACITY		BULK CAPACITY	THREADS	BOX QTY.
		(OZ.)	(GMS)			
G70F-HP18/B	43040	14	400	500	1/8" BSPT	16
G70F-HP18/M	43041	14	400	500	M10 × 1	16
★ G70F-HP18/N	43042	14	400	500	1/8" NPT	16

★ Best Seller


Aluminium die cast head with unique bulk loader which doubles as an air bleeder

Compression Spring



G80

UNIQUE ADJUSTABLE MECHANISM
HIGH PRESSURE / HIGH VOLUME

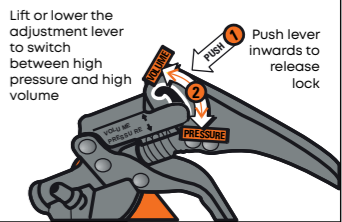

SPECIFICATIONS

DEVELOPS	UPTO 6,000 PSI	UPTO 413 BAR
DELIVERS	UPTO 1.30 OZ. / 40 STROKES	UPTO 0.90 GM / STROKE

ORDERING INFORMATION

CAT NR.	ORD NR.	CARTRIDGE CAPACITY		BULK CAPACITY	THREADS	BOX QTY.
		(OZ.)	(GMS)			
G80F-HP/B	43045	14	400	500	1/8" BSPT	10
★ G80F-HP/M	43046	14	400	500	M10 × 1	10
★ G80F-HP/N	43047	14	400	500	1/8" NPT	10
G85F-HP/B	43048	-	450	650	1/8" BSPT	10

★ Best Seller