


C型 規格頭 (Gネジ)

単位 mm

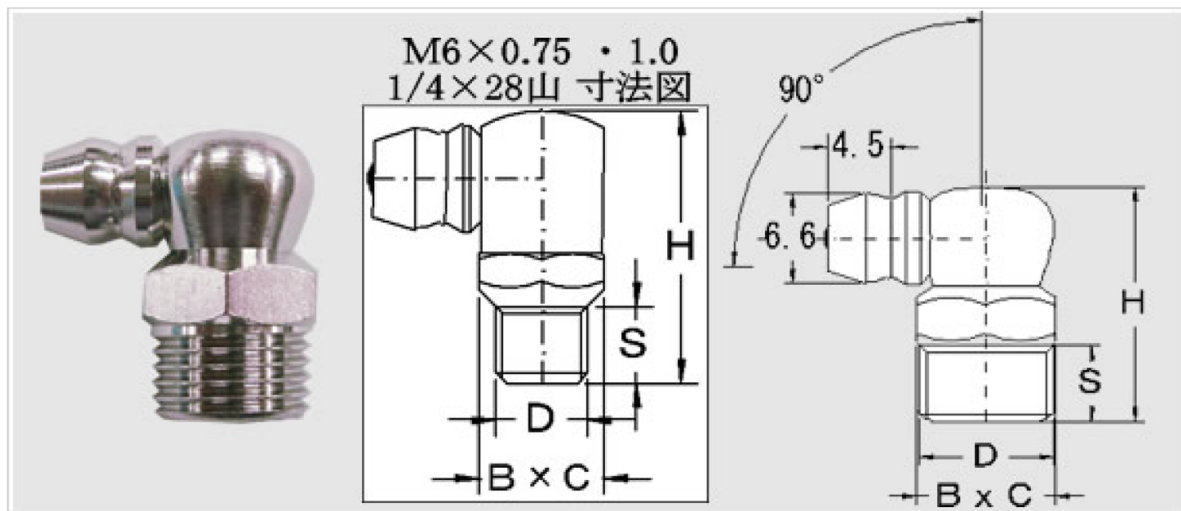

規格	EA品番	ネジD	寸 法		
			H	S	B × C
GNC1K	EA991CZ-91	G1/8	17	5.5	10
GNC2-28K	EA991CZ-92F	1/4 × 28山	17.5	5	8
GNC6M10K	EA991CZ-96	M6 × 1.0	17.5	5	8
GNC8M12K	EA991CZ-98	M8 × 1.25	17.5	5.5	10
GNC10M10K	EA991CZ-100	M10 × 1.0	21.5	8	10