


油圧ジャッキ
EA993BJ-2S、-2~100



●スチール製

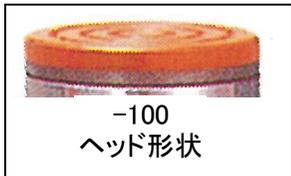


横方向の使用も可能です！！

○印の方向90°に傾けた横方向に使用できます。
※横方向でのストロークは油量の関係で50%になります。



取扱い中止
取扱い中止
取扱い中止
取扱い中止
取扱い中止
取扱い中止

品番	能力	最低高 (mm)	最高揚高 (mm)	ストローク (mm)	補助ネジ (mm)	ベースサイズ (W)×(D)mm	ハンドル長 (mm)	重量 (kg)
EA993BJ-2S	2t	150	285	85	50	65×110	330	2.1
EA993BJ-2		180	345					2.3
EA993BJ-3	3t	190	365	115	60	72×115	380	2.6
EA993BJ-4	4t		375					4
EA993BJ-5	5t	200	390	120	70	82×142	545	4.5
EA993BJ-7	7t							90×151
EA993BJ-10	10t	240	470	150	80	106×166	605	8
EA993BJ-15	15t	265	510	165		118×180		10.8
EA993BJ-20	20t	270	430	160	-	128×182	800	13.2
EA993BJ-30	30t	280	440			142×192		18.7
EA993BJ-50	50t	305	475	170	-	237×188	1000	37
EA993BJ-100	100t		450	145		265×318		93


-2S

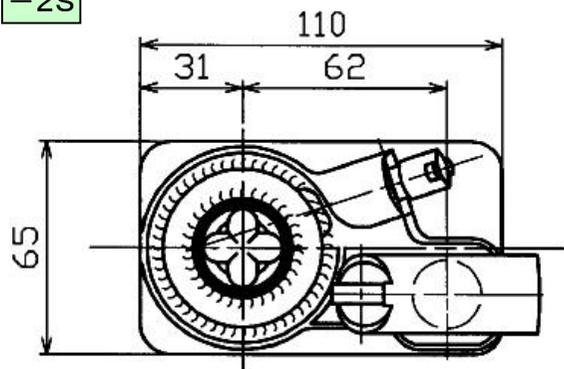

-2

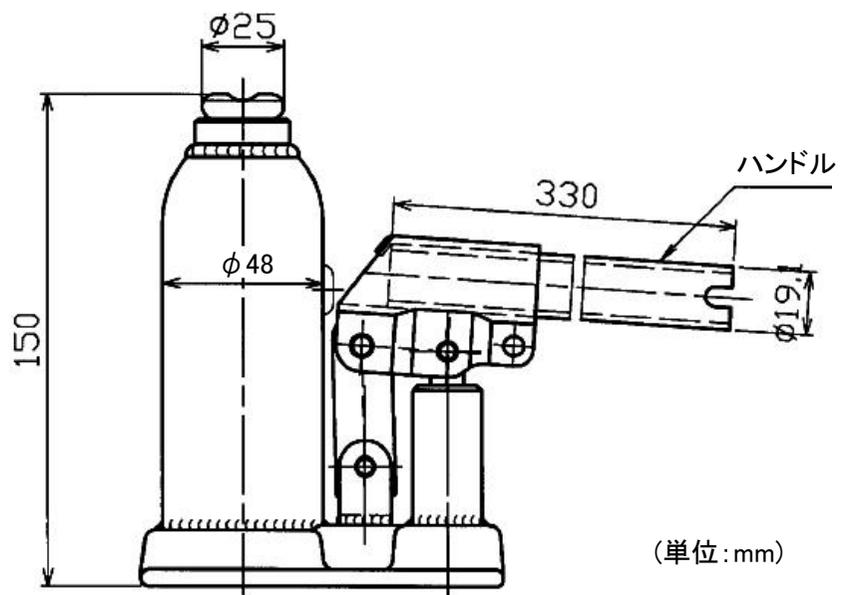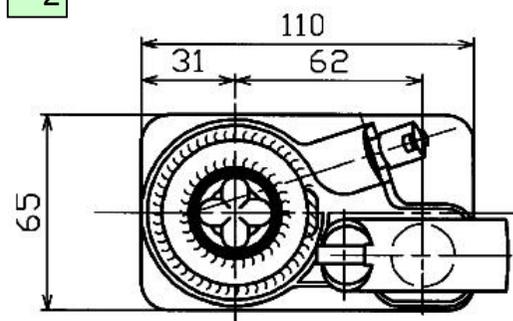


(単位:mm)


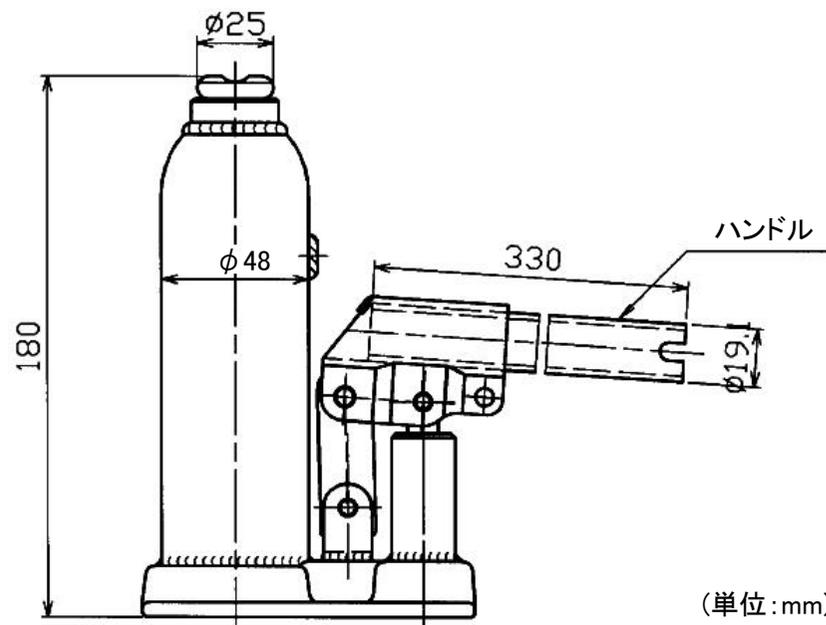


(単位:mm)


-3

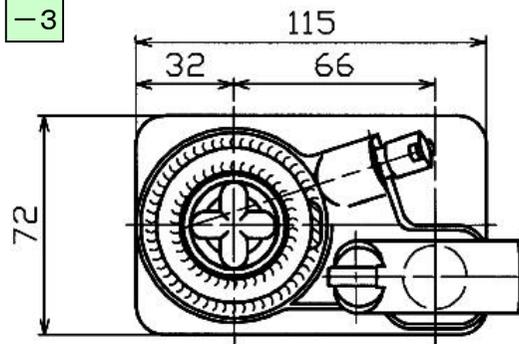





-4

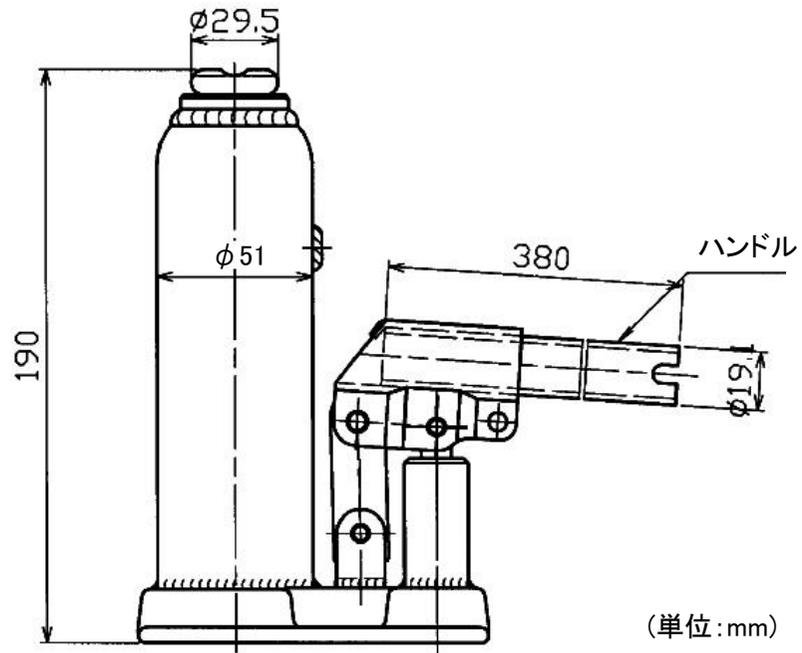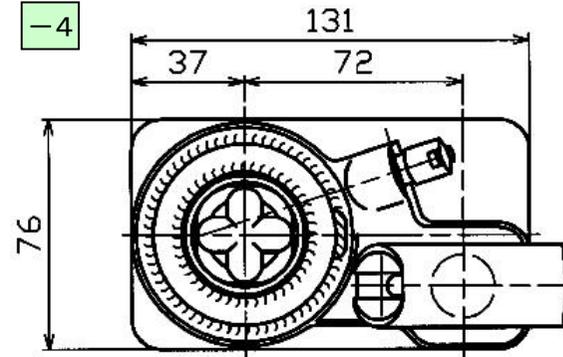

(単位:mm)




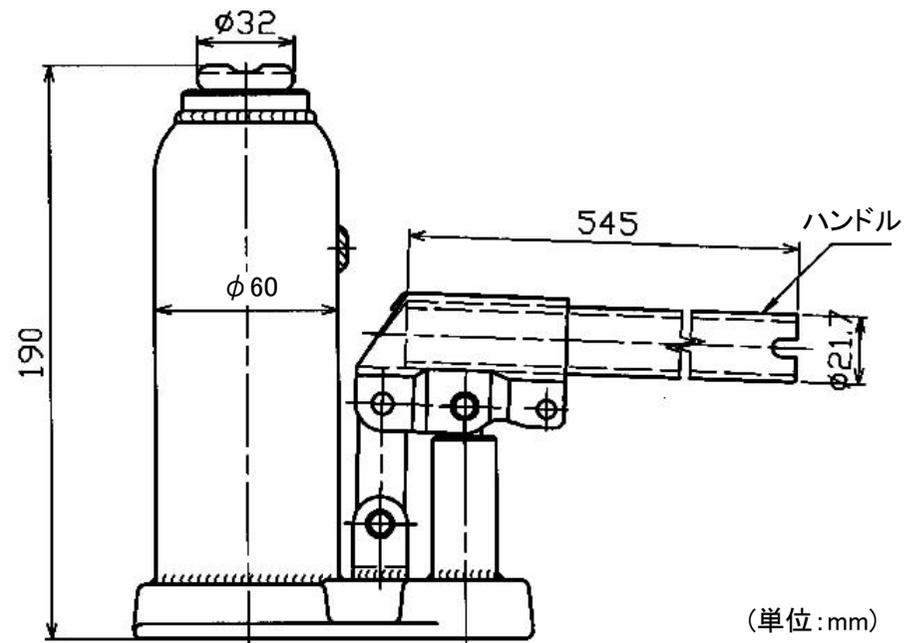






(単位:mm)

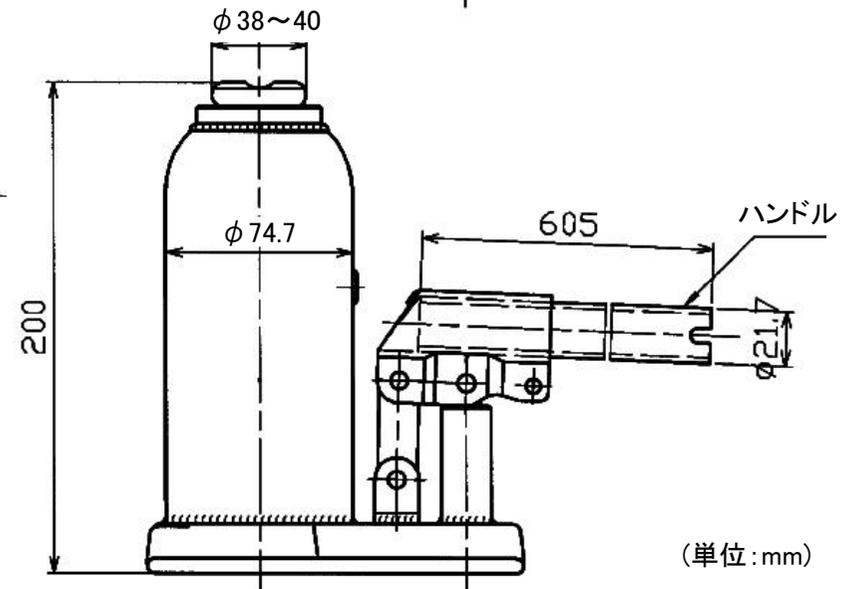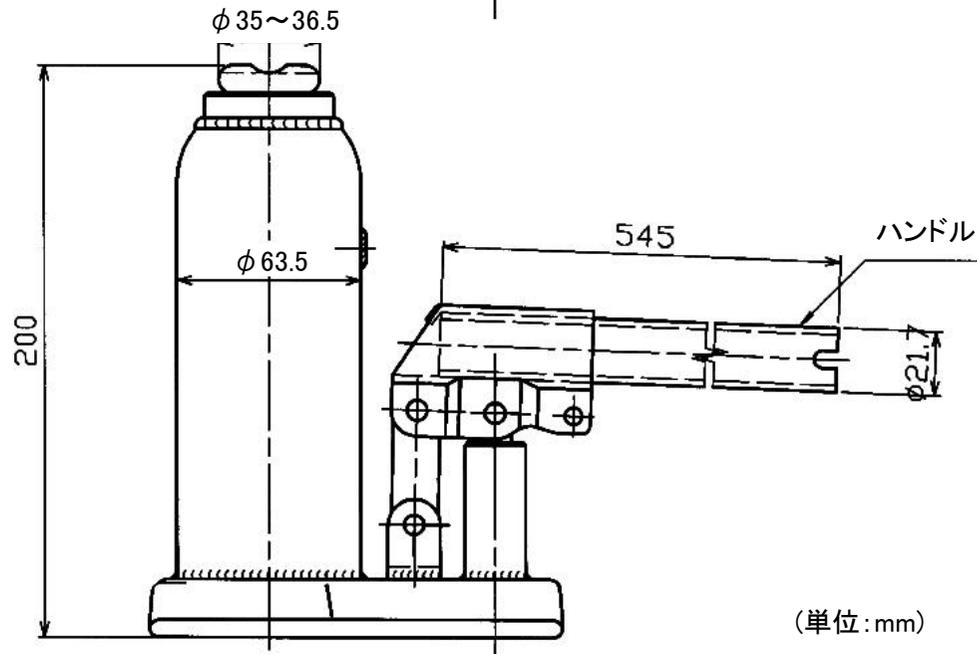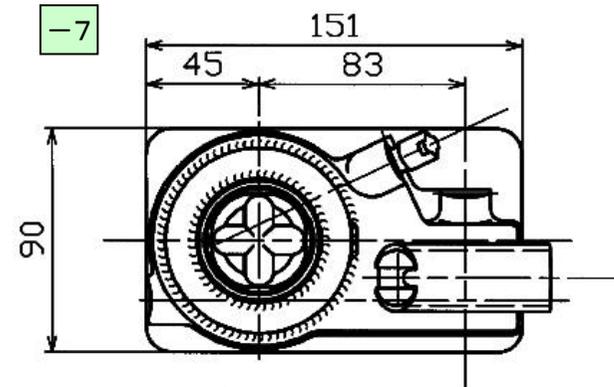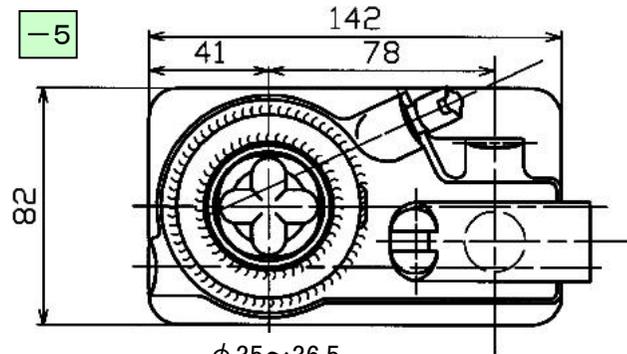

(単位: mm)

(単位: mm)

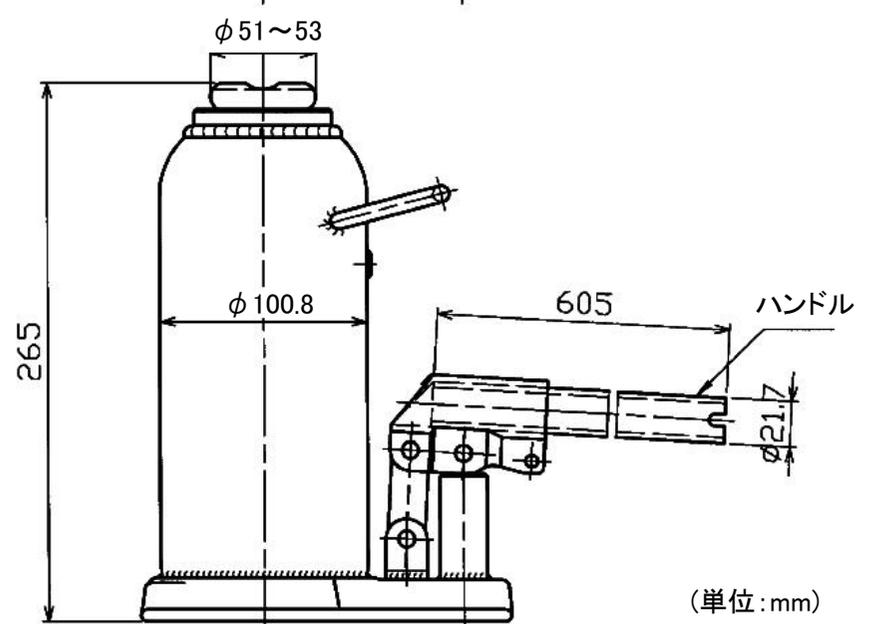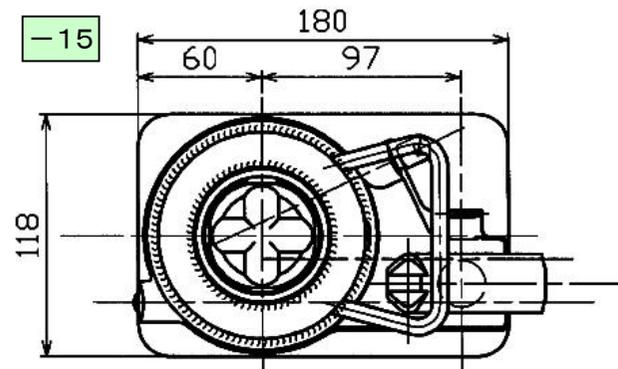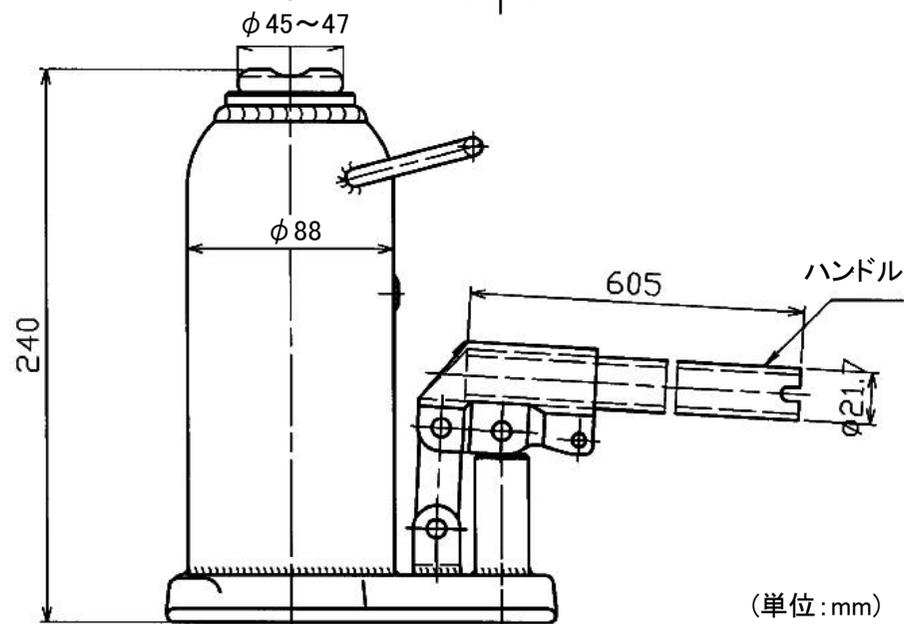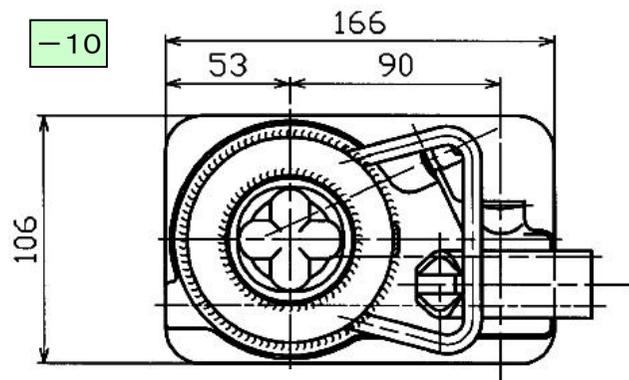

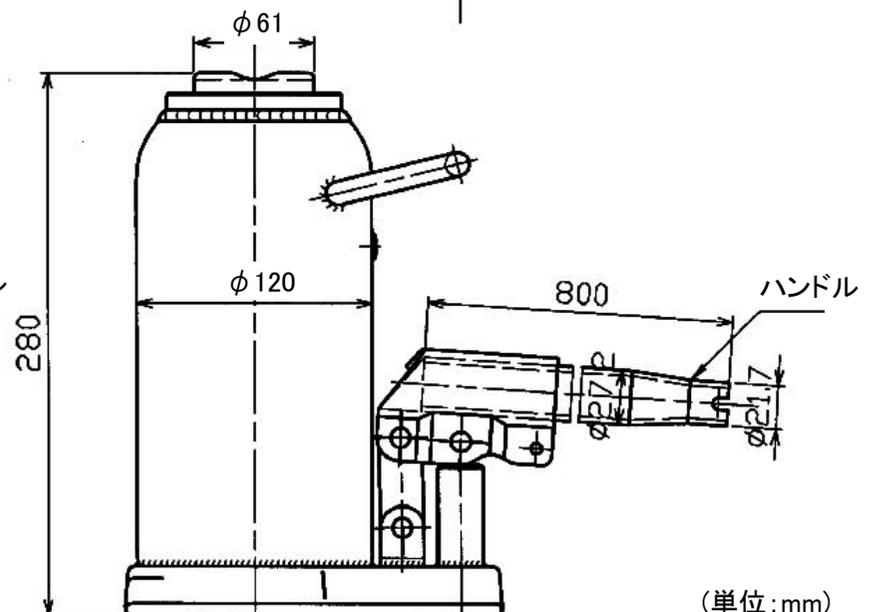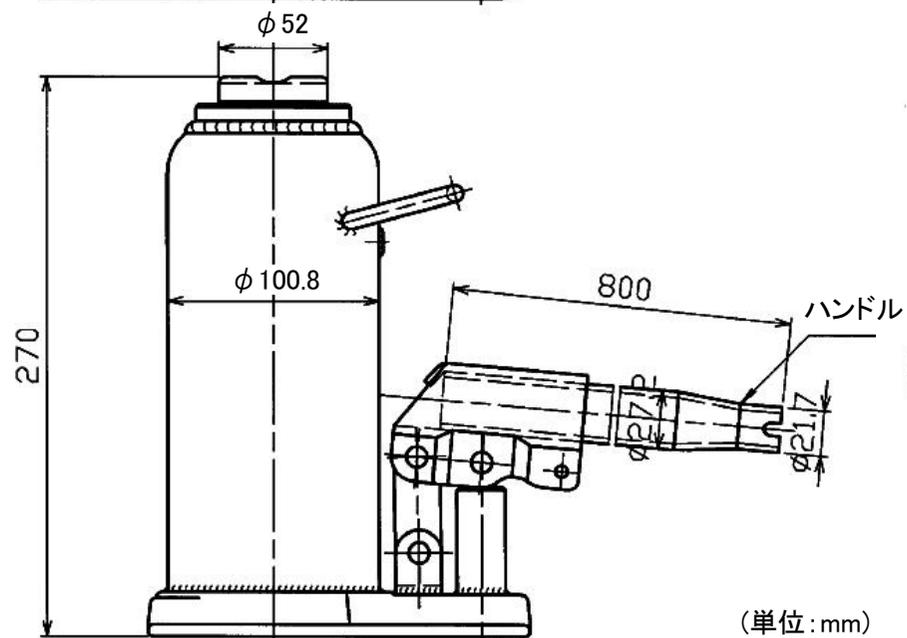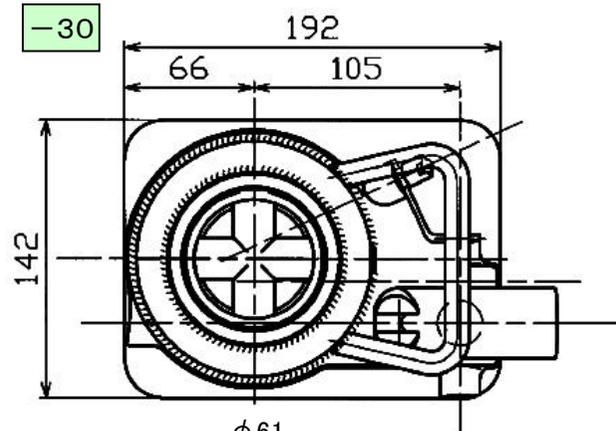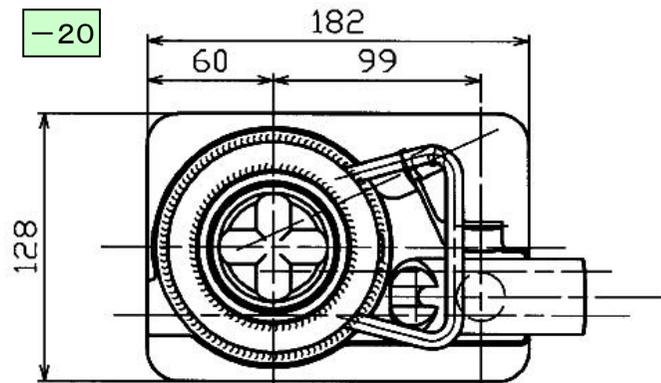

(単位: mm)

(単位: mm)

