



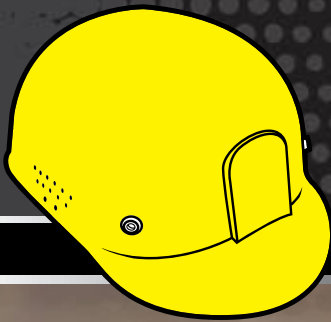

Diamond[™]

CAP STYLE BUMP CAP

4-Point Pinlock Molded Suspension

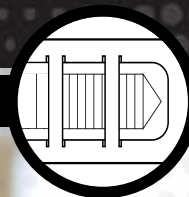

Great Fit • Great Comfort • Great Value

- Does NOT Meet ANSI Z89.1 2003 Requirements.
- High Density Polyethylene Shell
- Perforated Sides for Ventilation
- Easily Adjustable Pinlock Molded Suspension



www.radians.com

Diamond™

Bump Cap Style - 4-Point Molded Suspension

Molded Suspension

Points of attachment	4
Headband sizes	6 5/8" to 7 5/8"
Sizing location	Rear



Easy Size Adjustment

Perforated Sides
Allows crown ventilation

4-Point Molded Suspension
For proper crown height positioning

Imprinting
NOT Available



CAUTION:

Bump caps are not designed to protect against impact from falling or glancing objects. Does **NOT** meet ANSI Z89.1-2003 requirements.

Diamond™

Part No.	Color
302-WHITE	White EA998CN-1
302-BLUE	Blue EA998CN-3
302-ORANGE	Orange
302-GREEN	Green
302-YELLOW	Yellow EA998CN-2
302-RED	Red

Packaging

Unit	Qty
EA - (12" l x 8" w x 6" h)	1
Case - (19" l x 15" w x 16" h)	30



Michigan

Toll Free: 800-483-2462
Phone: 616-866-2220 / Fax: 616-866-3615

Nevada

Toll Free: 877-723-9378
Phone: 775-284-8295 / Fax: 775-284-8291

Tennessee

Toll Free: 877-723-4267
Phone: 901-388-7776 / Fax: 901-266-2558