


Energizer® Cap Light

ENCAP22

The *Energizer®* Cap Light is an ultra-slim solution designed to light your way, while keeping both hands free. For maximum convenience, the *Energizer* Cap Light can be easily clipped above the brim to provide an unobstructed view, and also pivots up to 90 degrees to direct light precisely where needed. The red LED provides discreet night vision, while the white LED delivers high-performance directional illumination. The Next-Push Off feature allows consumers to switch the light off without pressing through different light cycles. Designed to be rugged, yet compact and lightweight, the *Energizer* Cap Light is ideal for outdoor activities and offers an exceptional combination of brightness, runtime and durability.

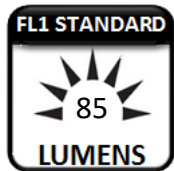


Provides 325 Lumens of Light



Provides Run Time of 4 hours



Sustains 2 Meter Drop Test.

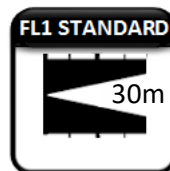

Illuminates objects up to 30 meters away



Water Resistant – works after splashing water on all sides

- ✓ Rugged metal clip to fasten securely
- ✓ Pivots up to 90 degrees to direct light where needed
- ✓ Red LED for discreet night vision
- ✓ Next-Push Off feature to switch the light off without cycling through different modes

- ✓ Up to 5X brighter than standard LED Technology
- ✓ Excellent Run Time



- ✓ Features LED Technology
- ✓ Operates on 2 AAA Batteries

Weight Excluding Batteries:

18 Grams / .63 Ounces

Dimensions:

70mm x 31mm x 27mm / 2.8" x 1.2" x 1.1"

NUMBER OF OPERATING MODES: 3

Mode	Lumens (lm)	Runtime (h)	Beam Distance (m)
High	85	4	30
Low	30	18	18
Red			

CE RoHS

EMC, EN62471, FCC

Energizer® MAX. Alkaline / E92